


PREMIUM CARD HYDROVAR


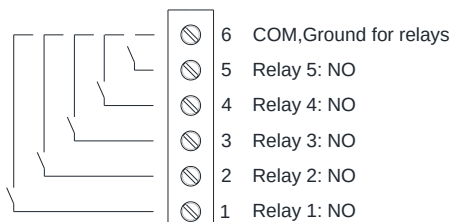


X4


12	→	Ground for external sensor 4
11		Actual value current / voltage input sensor 4
10	+24VDC	Power supply for external sensor 4
9	→	Ground for external sensor 3
8		Actual value current / voltage input sensor 3
7	+24VDC	Power supply for external sensor 3
6	→	Ground for analog output signal 2
5		Analog output signal 2, 0-10 VDC
4	→	Ground for analog output signal 1
3		Analog output signal 1, 4-20 mA
2	→	Ground for configurable digital input 2
1		Configurable digital input 2

X3


NHG_PREMIUM CARD_B_SC

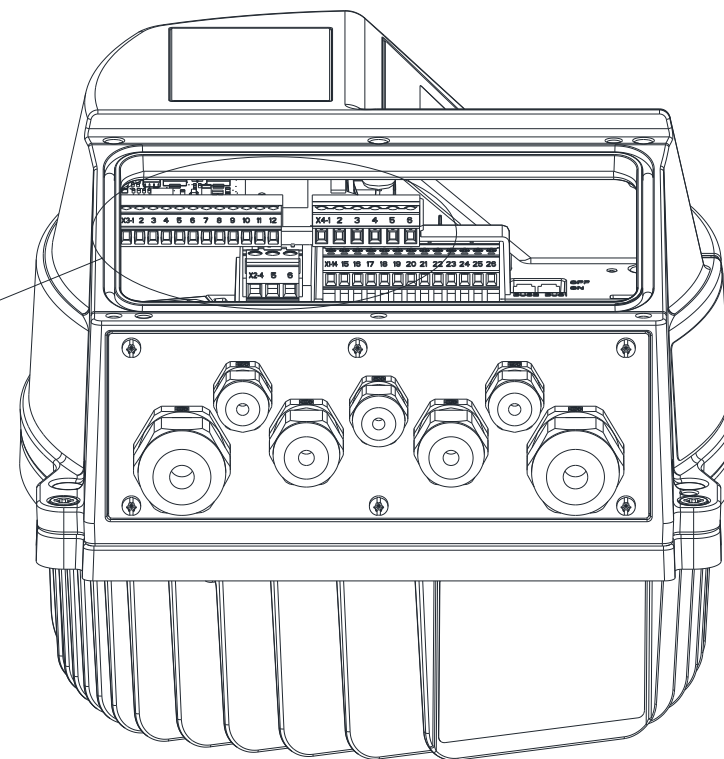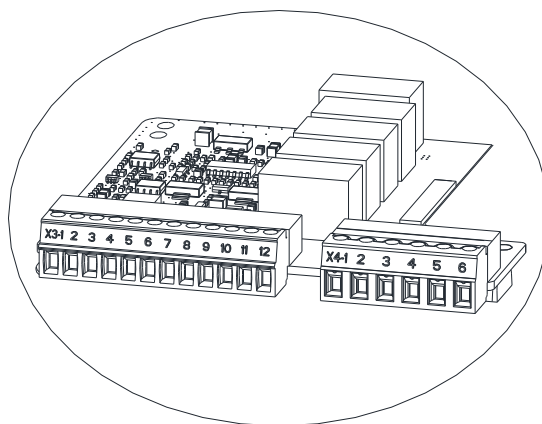

HVNG-IDM_PREMIUM-CARD_A_SC

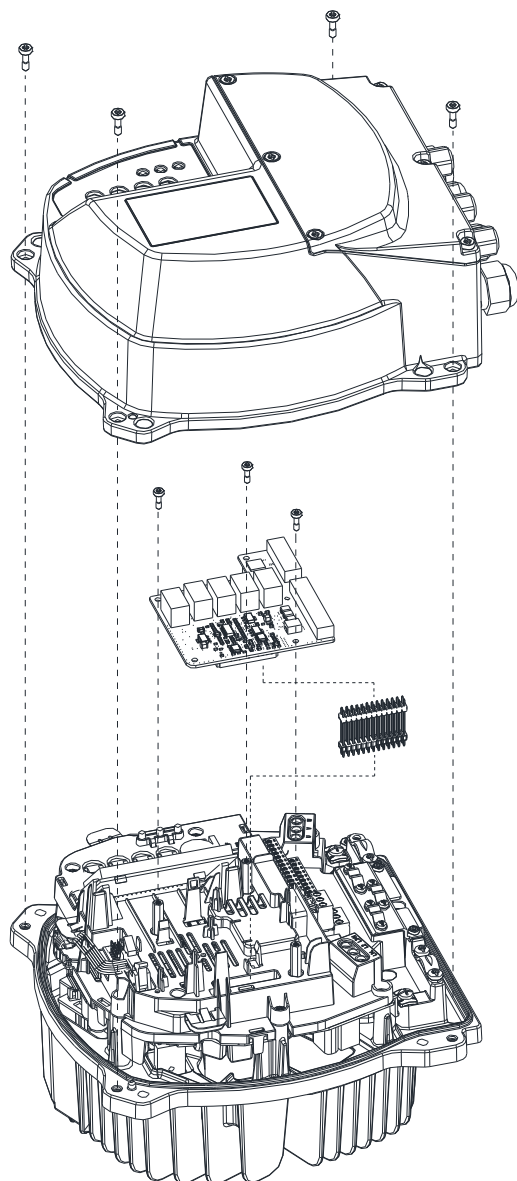

HVNG-IDM_PREMIUM-CARD-FIX-1_B_SC

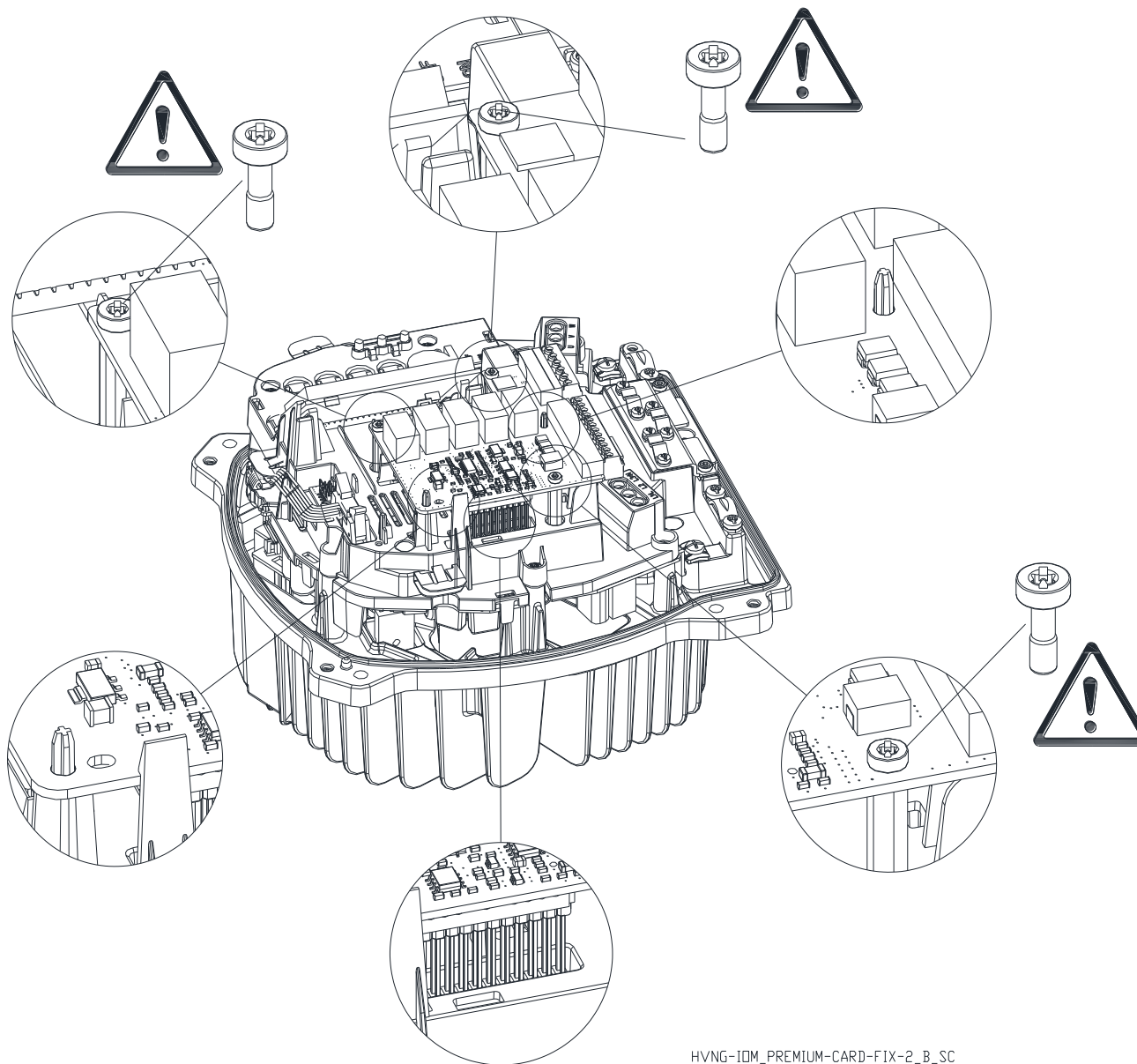

HVNG-IDM_PREMIUM-CARD-FIX-2_B_SC