


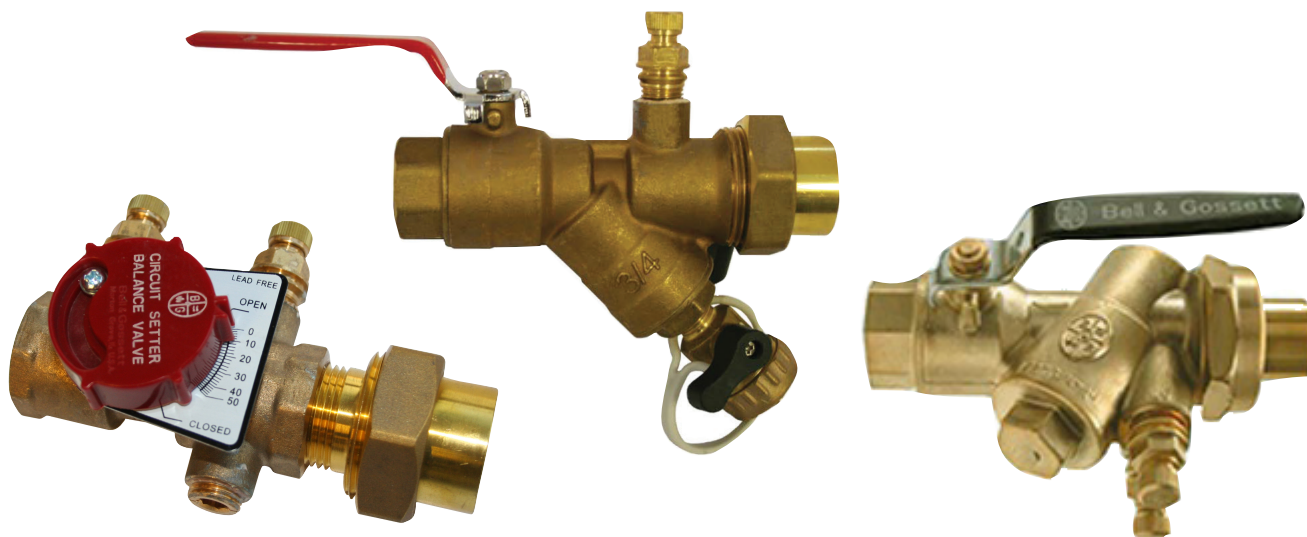


Coil hook-up

Replacement parts

Table of contents

Valve model	Page
UBY – Shut-off valve / Y-strainer	1
UBV – Ball shut-off valve	2
UA – Union accessory	3
MC – Circuit setter	4
AC – Circuit sentry	5
AF – Flo setter II	6
AA – Ultra setter	7
AU – Ultra setter compact	8
AX – Ultra setter compact	9
Miscellaneous & tailpieces	10

UBY – Shut-off valve / Y-strainer

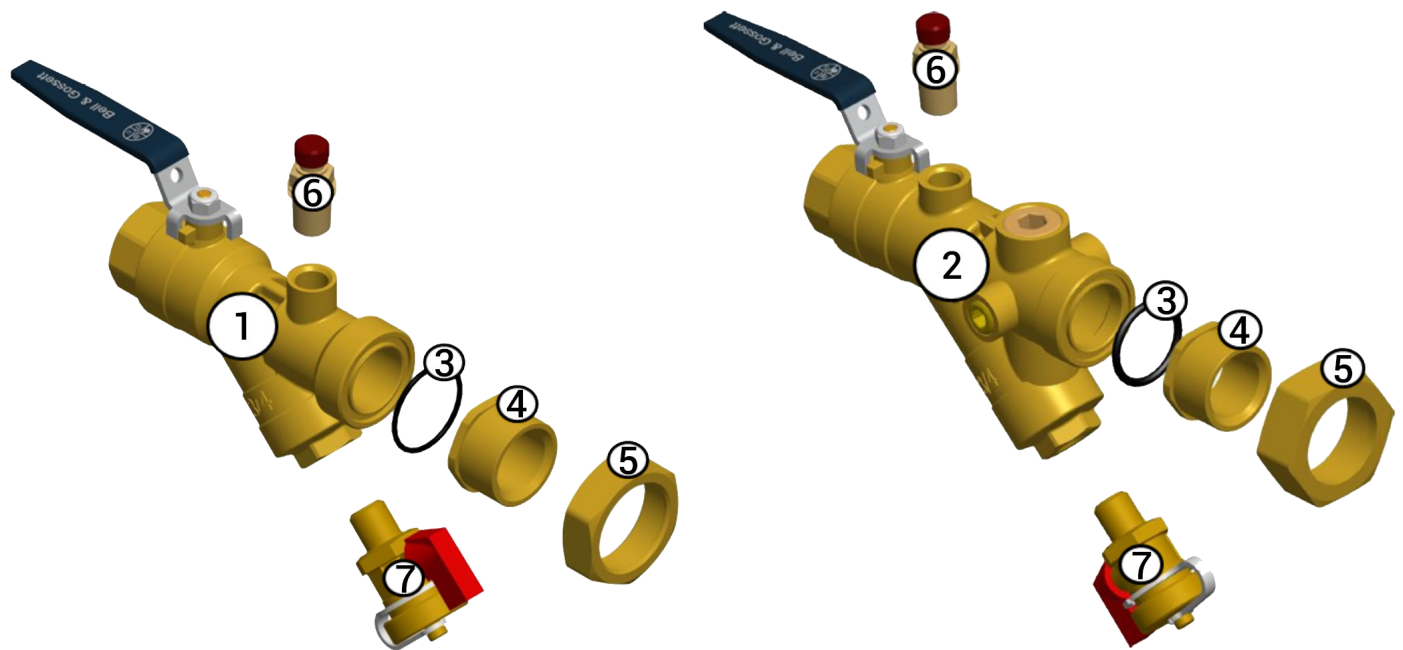

Fixed/inlet size	Fixed connection	Body less bypass	Body with bypass	O-ring	Union nut	P/T port	Drain valve	Union tailpiece*
Item no.		1	2	3	5	6	7	4
½"	NPTF	V100673	V57461	V57795	V58570	V58050	V58052	
	SWTF	V100674	V57462	V57795	V58570	V58050	V58052	
¾"	NPTF	V100675	V57463	V57801	V1000866	V58050	V58052	
	SWTF	V100676	V57464	V57801	V1000866	V58050	V58052	
1"	NPTF	V100677	V57465	V57809	V1000867	V58050	V58052	
	SWTF	V100678	V57466	V57809	V1000867	V58050	V58052	
1¼"	NPTF	V100679	V57469	V57817	V1000868	V58050	V58052	
	SWTF	V100680	V57470	V57817	V1000868	V58050	V58052	
1½"	NPTF	V100681	V57471	V57825	V1000869	V58050	V58052	
	SWTF	V100682	V57472	V57825	V1000869	V58050	V58052	
2"	NPTF	V100683	V57473	V57833	V1000870	V58050	V58052	
	SWTF	V100684	V57474	V57833	V1000870	V58050	V58052	

*See page 11 for Union tailpieces


Strainer less bypass body

Size	Strainer screen
½" & ¾"	V1000863
1" & 1¼"	V1000864
1½" & 2"	V1000216

Strainer with bypass body

Size	Strainer screen
½" & ¾"	V1000214
1" & 1¼"	V1000215
1½" & 2"	V1000216


UBV – Ball shut-off valve

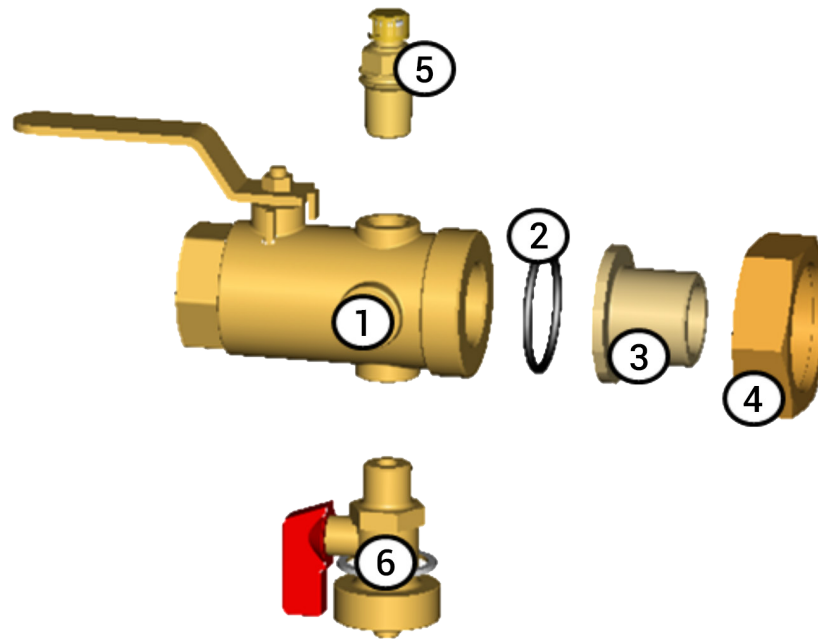

Fixed/inlet size	Fixed connection	Body	O-ring	Union nut	P/T port	Drain valve	Union tailpiece*
Item no.		1	2	4	5	6	3
½"	NPTF	V57421	V57795	V58570	V58050	V58052	
	SWTF	V57422	V57795	V58570	V58050	V58052	
¾"	NPTF	V57423	V57801	V1000866	V58050	V58052	
	SWTF	V57424	V57801	V1000866	V58050	V58052	
1"	NPTF	V57425	V57809	V1000867	V58050	V58052	
	SWTF	V57426	V57809	V1000867	V58050	V58052	
1¼"	NPTF	V57427	V57817	V1000868	V58050	V58052	
	SWTF	V57428	V57817	V1000868	V58050	V58052	
1½"	NPTF	V57429	V57825	V1000869	V58050	V58052	
	SWTF	V57430	V57825	V1000869	V58050	V58052	
2"	NPTF	V57431	V57833	V1000870	V58050	V58052	
	SWTF	V57432	V57833	V1000870	V58050	V58052	

*See page 11 for Union tailpieces


UA – Union accessory

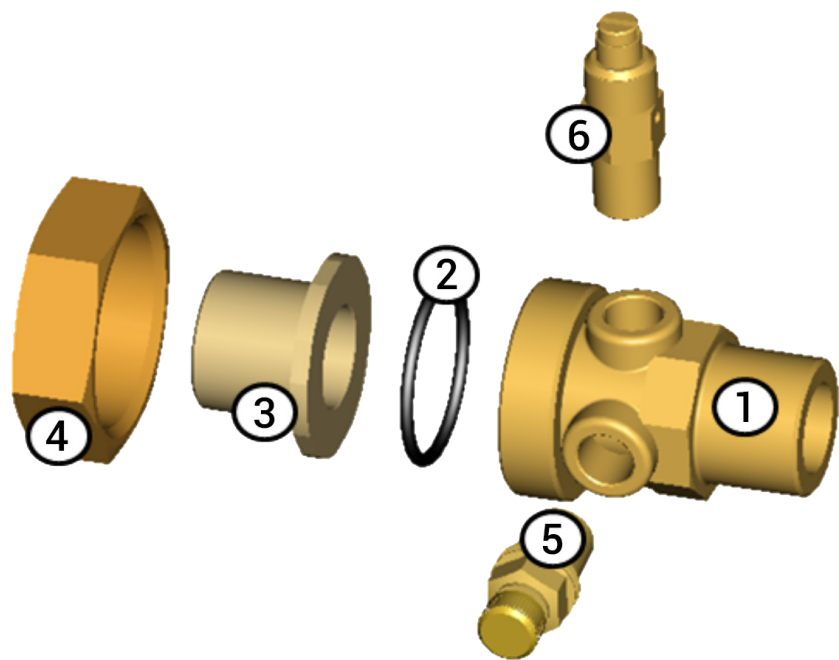

Fixed/inlet size	Fixed connection	Body	O-ring	Union nut	P/T port	Drain valve	Union tailpiece*
Item no.		1	2	4	5	6	3
1/2"	NPTF	V57441	V57795	V58570	V58050	V58051	
	SWTF	V57442	V57795	V58570	V58050	V58051	
3/4"	NPTF	V57443	V57801	V1000866	V58050	V58051	
	SWTF	V57444	V57801	V1000866	V58050	V58051	
1"	NPTF	V57445	V57809	V1000867	V58050	V58051	
	SWTF	V57446	V57809	V1000867	V58050	V58051	
1 1/4"	NPTF	V57447	V57817	V1000868	V58050	V58051	
	SWTF	V57448	V57817	V1000868	V58050	V58051	
1 1/2"	NPTF	V57449	V57825	V1000869	V58050	V58051	
	SWTF	V57450	V57825	V1000869	V58050	V58051	
2"	NPTF	V57451	V57833	V1000870	V58050	V58051	
	SWTF	V57452	V57833	V1000870	V58050	V58051	

*See page 11 for Union Tailpieces


MC – Circuit setter

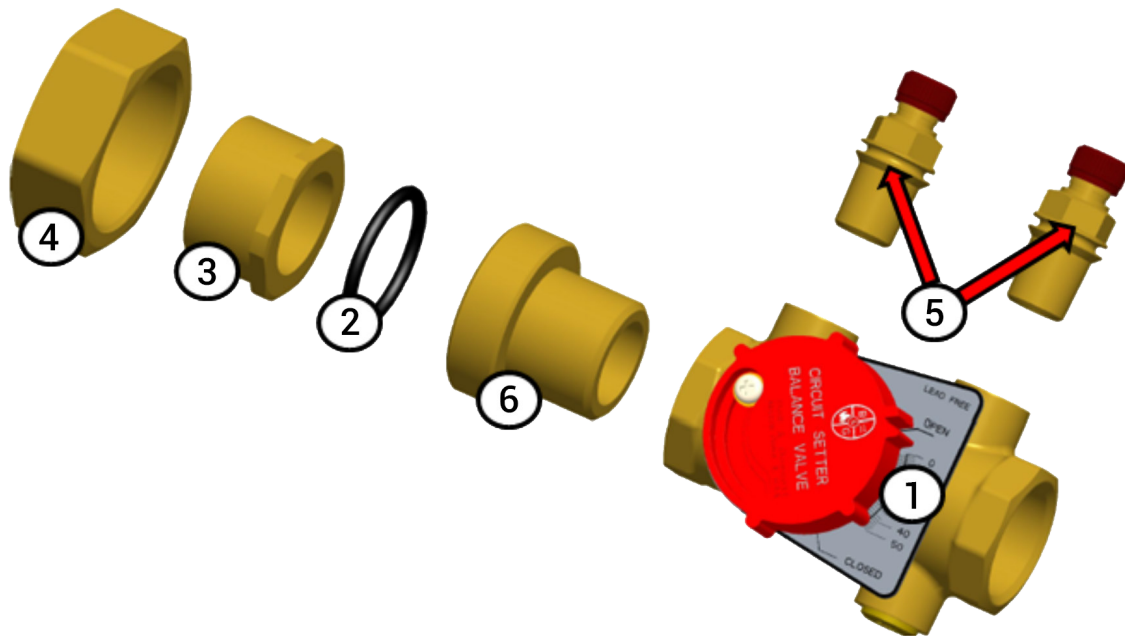

Fixed/inlet size	Fixed connection	Body less bypass	SWTF fixed adapter	O-ring	Union nut	P/T port	Drain valve	Union tailpiece*
Item no.		1	Not shown	2	4	5	6	3
½"	NPTF	117414LF	N/A	V57795	V58570	V58050	V57401	
	SWTF	117414LF	V57835	V57795	V58570	V58050	V57401	
¾"	NPTF	117415LF	N/A	V57801	V1000866	V58050	V57403	
	SWTF	117415LF	V57836	V57801	V1000866	V58050	V57403	
1"	NPTF	117416LF	N/A	V57809	V1000867	V58050	V57405	
	SWTF	117416LF	V57837	V57809	V1000867	V58050	V57405	
1¼"	NPTF	117103LF	N/A	V57817	V1000868	V58050	V57407	
	SWTF	117103LF	V57838	V57817	V1000868	V58050	V57407	
1½"	NPTF	117104LF	N/A	V57825	V1000869	V58050	V57409	
	SWTF	117104LF	V57839	V57825	V1000869	V58050	V57409	
2"	NPTF	117105LF	N/A	V57833	V1000870	V58050	V57411	
	SWTF	117105LF	V57840	V57833	V1000870	V58050	V57411	

*See page 11 for Union tailpieces


AC – Circuit sentry

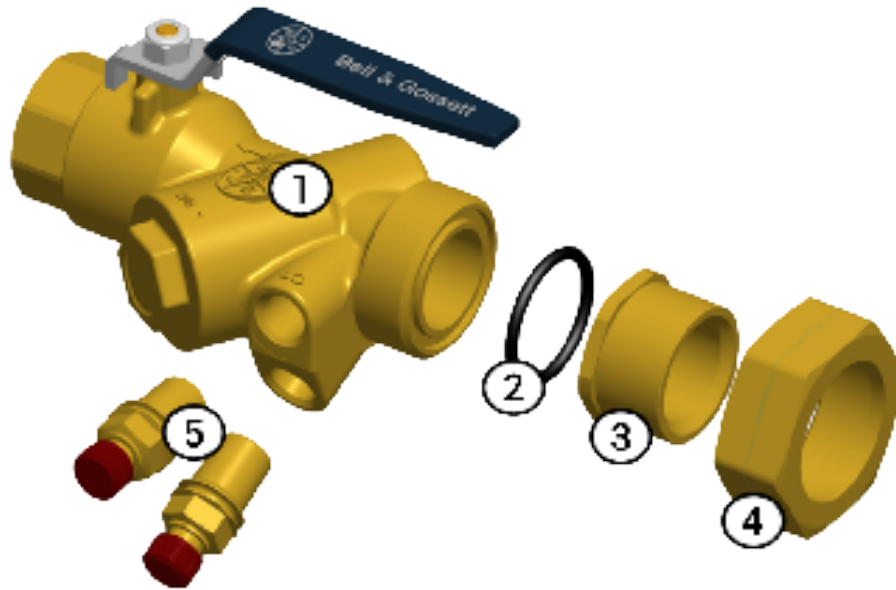

Body type	Fixed/inlet size	Fixed connection	Body	O-ring	Union nut	P/T port	Union tailpiece*	Extended handles
Item No.			1	2	4	5	3	Not Shown
A	½"	NPTF	V100622	V57795	V58570	V58050		V57753
		SWTF	V100623	V57795	V58570	V58050		V57753
	¾"	NPTF	V100624	V57801	V1000866	V58050		V57753
		SWTF	V100625	V5801	V1000866	V58050		V57753
	1"	NPTF	V100626	V57809	V1000867	V58050		V59181
		SWTF	V100627	V57809	V1000867	V58050		V59181
B	1¼"	NPTF	V100628	V57809	V1000867	V58050		V59181
		SWTF	V100629	V57809	V1000867	V58050		V59181
	1½"	NPTF	V100630	V57817	V1000868	V58050		V57757
		SWTF	V100631	V57817	V1000868	V58050		V57757
	2"	NPTF	V100632	V57825	V1000869	V58050		V57757
		SWTF	V100633	V57825	V1000869	V58050		V57757
	2"R	NPTF	N/A	V57833	V1000870	V58050		V57757
		SWTF	N/A	V57833	V1000870	V58050		V57757
C	1½"L	NPTF	V100634	V57825	V1000869	V58050		V57757
		SWTF	V100635	V57825	V1000869	V58050		V57757
	2"	NPTF	V100636	V57833	V1000870	V58050		V59182
		SWTF	V100637	V57833	V1000870	V58050		V59182
	2½"	NPTF	N/A	N/A	N/A	V58050		N/A
		SWTF	N/A	N/A	N/A	V58050		N/A

*See page 11 for Union Tailpieces


AF – Flo setter II

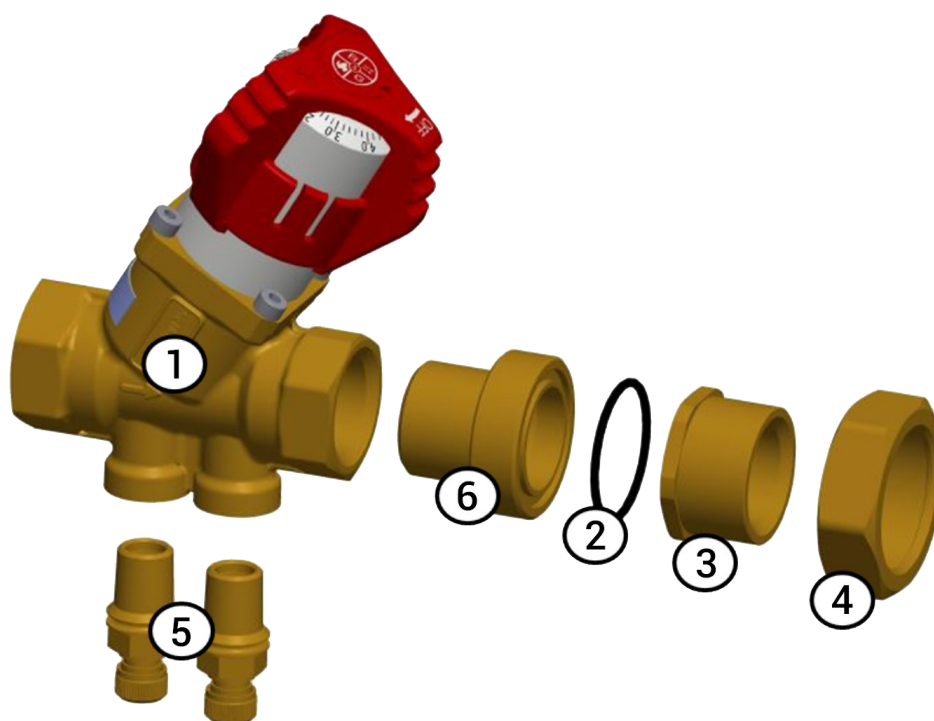

Fixed/inlet size	Fixed connection	Body	SWTF fixed adapter	O-ring	Union nut	P/T port	Tailpiece adapter	Optional ball valve	Union tailpiece*
Item no.		1	Not shown	2	4	5	6	Not shown	3
½"	NPTF	117630	N/A	V57795	V58570	V58050	V57401	V59115	
	SWTF	117630	V57835	V57795	V58570	V58050	V57401	V59115	
¾"	NPTF	117632	N/A	V57801	V1000866	V58050	V57403	V59116	
	SWTF	117632	V57836	V57801	V1000866	V58050	V57403	V59116	
1"	NPTF	117643	N/A	V57809	V1000867	V58050	V57405	V59117	
	SWTF	117643	V57837	V57809	V1000867	V58050	V57405	V59117	
1¼"	NPTF	117636	N/A	V57817	V1000868	V58050	V57407	V59118	
	SWTF	117636	V57838	V57817	V1000868	V58050	V57407	V59118	
1½"	NPTF	117637	N/A	V57825	V1000869	V58050	V57409	V59119	
	SWTF	117637	V57839	V57825	V1000869	V58050	V57409	V59119	
2"	NPTF	117638	N/A	V57833	V1000870	V58050	V57411	V59120	
	SWTF	117638	V57840	V57833	V1000870	V58050	V57411	V59120	


*See page 11 for Union tailpieces

AA – Ultra setter

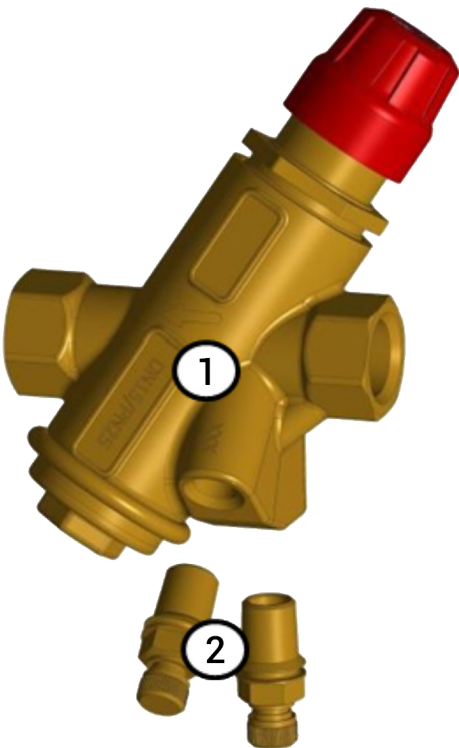

Fixed/inlet size	Fixed connection	Body	SWTF fixed adapter	P/T port	Optional ball valve
Item no.		1	Not shown	2	Not shown
½" H	NPTF	117595	N/A	V58050	V59115
	SWTF	117595	V57835	V58050	V59115
½" L	NPTF	117596	N/A	V58050	V59115
	SWTF	117596	V57835	V58050	V59115
¾" H	NPTF	117597	N/A	V58050	V59116
	SWTF	117597	V57836	V58050	V59116
¾" L	NPTF	117598	N/A	V58050	V59116
	SWTF	117598	V57836	V58050	V59116
1" H	NPTF	117599	N/A	V58050	V59117
	SWTF	117599	V57837	V58050	V59117
1" L	NPTF	117600	N/A	V58050	V59117
	SWTF	117600	V57837	V58050	V59117
1¼"	NPTF	117601	N/A	V58050	V59118
	SWTF	117601	V57838	V58050	V59118


AU – Ultra setter compact

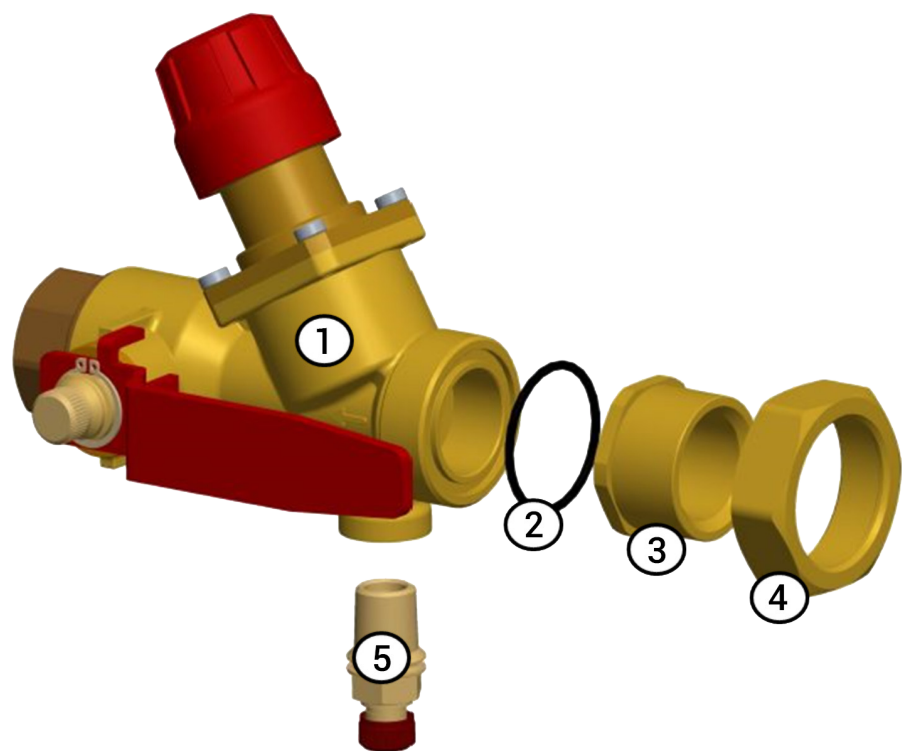

Fixed/inlet size	Fixed connection	Body	SWTF fixed adapter	O-ring	Union nut	P/T port	Union tailpiece*
Item no.		1	Not shown	2	4	5	3
½" UL	NPTF	117520	N/A	V57795	V58570	V58050	
	SWTF	117520	V57835	V57795	V58570	V58050	
½" L	NPTF	117521	N/A	V57795	V58570	V58050	
	SWTF	117521	V57835	V57795	V58570	V58050	
½" H	NPTF	117522	N/A	V57795	V58570	V58050	
	SWTF	117522	V57835	V57795	V58570	V58050	
½" UH	NPTF	117523	N/A	V57795	V58570	V58050	
	SWTF	117523	V57835	V57795	V58570	V58050	
¾" L	NPTF	117524	N/A	V57801	V1000866	V58050	
	SWTF	117524	V57836	V57801	V1000866	V58050	
¾" H	NPTF	117525	N/A	V57801	V1000866	V58050	
	SWTF	117525	V57836	V57801	V1000866	V58050	

*See page 11 for Union tailpieces

AX – Ultra setter compact

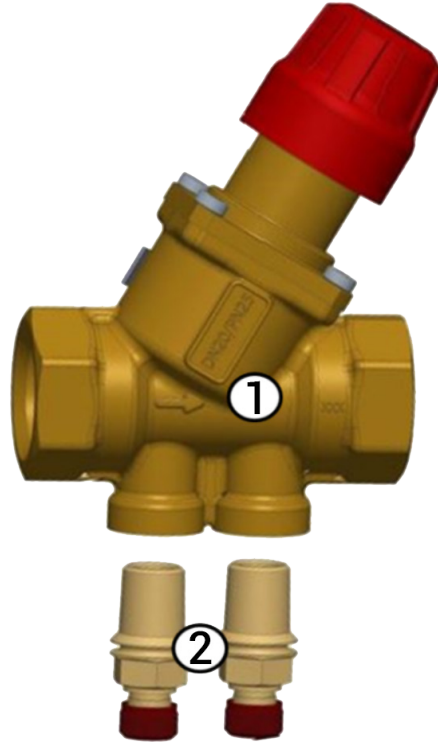

Fixed/inlet size	Fixed connection	Body	SWTF fixed adapter	P/T port	Optional ball valve
Item no.		1	Not shown	2	Not shown
½" UL	NPTF	117520	N/A	V58050	V59115
	SWTF	117520	V57835	V58050	V59115
½" L	NPTF	117521	N/A	V58050	V59115
	SWTF	117521	V57835	V58050	V59115
½" H	NPTF	117522	N/A	V58050	V59115
	SWTF	117522	V57835	V58050	V59115
½" UH	NPTF	117523	N/A	V58050	V59115
	SWTF	117523	V57835	V58050	V59115
¾" L	NPTF	117524	N/A	V58050	V59116
	SWTF	117524	V57836	V58050	V59116
¾" H	NPTF	117525	N/A	V58050	V59116
	SWTF	117525	V57836	V58050	V59116
1"	NPTF	117526	N/A	V58050	V59117
	SWTF	117526	V57837	V58050	V59117
1¼"	NPTF	117527	N/A	V58050	V59118
	SWTF	117527	V57838	V58050	V59118
1½"	NPTF	117528	N/A	V58050	V59119
	SWTF	117528	V57839	V58050	V59119
2"	NPTF	117529	N/A	V58050	V59120
	SWTF	117529	V57840	V58050	V59120

Miscellaneous Parts and Extensions

Fixed/inlet size	Standard P/T ports	2" Extended P/T port	3½" P/T port extension*	Extended handles**	¼ STD port plug	O-ring	Union nut
½"	V58050	V57789	V57841	V57753	V58047	V57795	V58570
¾"	V58050	V57789	V57841	V57753	V58047	V57801	V1000866
1"	V58050	V57789	V57841	V59171	V58047	V57809	V1000867
1¼"	V58050	V57789	V57841	V57757	V58047	V57817	V1000868
1½"	V58050	V57789	V57841	V57757	V58047	V57825	V1000869
2"	V58050	V57789	V57841	V59182	V58047	V57833	V1000870

*Requires P/T port part number V58050

** For UBY, UBV, and AU valves only. See page 7 for AC extended handles.

Tail piece size	Fixed body size						
	Pipe style	½"	¾"	1"	1¼"	1½"	2"
⅜"	MNPT	V57993	V57996				
	FNPT	V57994	V57997				
	FSWT	V57995	V57998				
½"	MNPT	V57792	V57798	V57805	V57814		
	FNPT	V57793	V57999	V58001			
	FSWT	V57794	V58000	V58002			
¾"	MNPT		V57797	V57804	V57813	V57822	
	FNPT		V57799	V57807	V58004		
	FSWT	V57878	V57800	V58003	V58005		
1"	MNPT			V57808	V57812	V57821	V57830
	FNPT			V57806	V58006	V58008	
	FSWT				V58007	V58009	
1¼"	MNPT				V57811	V57820	V57829
	FNPT				V57816	V58010	V58012
	FSWT				V57815	V58011	V58013
1½"	MNPT					V57819	V57828
	FNPT					V57823	V58014
	FSWT					V57824	V58015
2"	MNPT						V57827
	FNPT						V57831
	FSWT						V57832

Xylem
8200 N. Austin Avenue
Morton Grove, IL 60053

Tel +1 847.966.3700
Fax +1 847.965.8379
xylem.com/bellgossett

This information is subject to revision without notice. Users are responsible for evaluating suitability for specific applications. Xylem makes no implied warranties including without limitation warranties as to fitness for a particular purpose. Xylem makes no representation regarding the completeness or accuracy of this information and is not liable for any direct or indirect damages arising from or relating to this information or its use.

© 2025 Xylem Inc. or its affiliate. All rights reserved. Bell & Gossett is a trademark of Xylem or one of its subsidiaries.

CP-550-PL R4 March 2025

xylem
Let's Solve Water