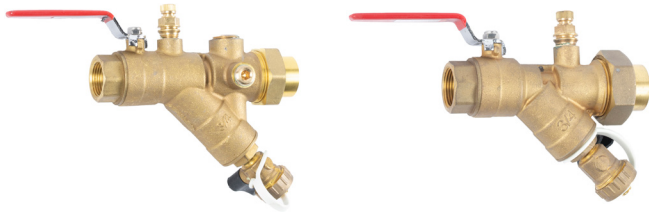


JOB:
REPRESENTATIVE:

 UNIT TAG:
 ENGINEER:
 CONTRACTOR:

 ORDER NUMBER:
 SUBMITTED BY:
 APPROVED BY:

 DATE:
 DATE:
 DATE:


Model UBY

Combination Ball Valve & Strainer

DESCRIPTION

The Bell & Gossett UBYC is a combination wye strainer, full port shut-off valve and union for use in HVAC systems. Strainers are furnished with a 20 mesh stainless steel screen, hose end drain valve for purging, and one pressure/temperature port for commissioning. A variety of pipe connections are available on both the fixed and union ends. An optional valve with Bypass port and additional pressure/temperature ports is available.

CONSTRUCTION

Body: Brass
Ball: Full Port Chrome Plated
Ball Seal: PTFE
Stem: Stainless Steel (Explosion Proof)
O-Rings: EPDM
Strainer: 20 Mesh Stainless Steel
Bypass Port Tap Size (optional):
 – 1/2" FNPT for sizes 1/2", 3/4" and 1"
 – 3/4" FNPT for sizes 1 1/4" and 1 1/2"
 – 1" FNPT for 2"

MAXIMUM WORKING PRESSURE


400 psig (2,758 kPa)

TEMPERATURE RANGE

-4°F (-20°C) to 250°F (121°C)


SCHEDULE

VALVE SIZE FIXED END	TAGGING INFORMATION	QUANTITY (NO PORT)	QUANTITY (WITH PORT)
1/2" Sweat Female			
1/2" NPT Female			
3/4" Sweat Female			
3/4" NPT Female			
1" Sweat Female			
1" NPT Female			
1 1/4" Sweat Female			
1 1/4" NPT Female			
1 1/2" Sweat Female			
1 1/2" NPT Female			
2" Sweat Female			
2" NPT Female			

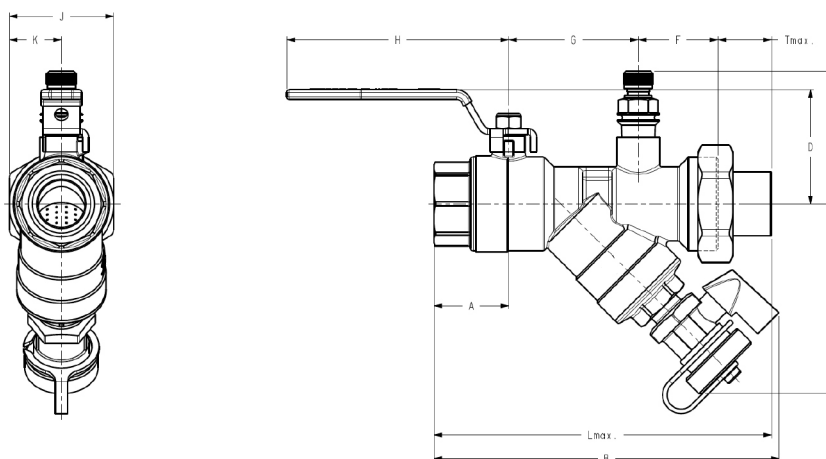

NOTE: THIS IS THE DEFAULT MODEL IF NO ADDITIONAL PT PORTS OR BYPASS IS REQUIRED.

Valve Size Fixed End	Connecon Fixed End	Cv	DIMENSIONS* INCH (mm)												Approx. Weight Lbs. (kg)
			A	B	C	D	E	F	G	H	J	K	T (Max)	L (Max)	
½"	Sweat Female	7.4	1.303 (33.1)	5.417 (137.59)	2.918 (74.12)	1.672 (42.46)	1.92 (48.77)	1.135 (28.82)	1.872 (47.56)	3.533 (89.74)	1.375 (34.93)	0.688 (14.46)	.6 (15.24)	7.140 (181.24)	1.5 (.68)
½"	NPT Female	7.4	1.055 (26.8)	5.169 (131.29)	2.918 (74.12)	1.672 (42.46)	1.92 (48.77)	1.135 (28.82)	1.872 (47.56)	3.533 (89.74)	1.375 (34.93)	0.688 (17.46)	.650 (16.51)	7.19 (182.63)	1.5 (.68)
¾"	Sweat Female	8	1.559 (39.6)	5.865 (148.96)	3.024 (76.82)	1.819 (46.2)	2.114 (53.7)	1.27 (32.25)	2.064 (52.43)	3.533 (89.74)	1.66 (42.16)	0.83 (21.08)	.85 (21.59)	7.717 (196)	1.81 (.82)
¾"	NPT Female	8	1.189 (30.2)	5.494 (139.56)	3.024 (76.82)	1.819 (46.2)	2.114 (53.7)	1.27 (32.25)	2.064 (52.43)	3.533 (89.74)	1.66 (42.16)	0.83 (21.08)	.8 (20.32)	7.667 (194.74)	1.81 (.82)
1"	Sweat Female	16	1.846 (46.9)	7.13 (181.1)	4.029 (102.33)	2.126 (54)	2.323 (59)	1.332 (33.83)	2.603 (66.11)	4.288 (108.93)	1.910 (48.51)	.955 (24.26)	1.010 (25.65)	9.233 (234.52)	3.06 (1.63)
1"	NPT Female	16	1.421 (36.1)	6.704 (170.29)	4.029 (102.33)	2.126 (54)	2.323 (59)	1.332 (33.83)	2.603 (66.11)	4.288 (108.93)	1.910 (48.51)	.955 (24.26)	.900 (22.86)	9.123 (231.72)	3.06 (1.63)
1¼"	Sweat Female	18	2.17 (55)	7.89 (200.4)	4.374 (111.1)	2.882 (73.2)	2.475 (62.87)	1.561 (39.65)	3.105 (78.87)	5.158 (131.02)	2.43 (61.72)	1.215 (30.86)	1.070 (27.18)	10.894 (276.71)	4.44 (2.01)
1¼"	NPT Female	18	1.634 (41.5)	7.357 (186.87)	4.374 (111.1)	2.882 (73.2)	2.475 (62.87)	1.561 (39.65)	3.105 (78.87)	5.158 (131.02)	2.43 (61.72)	1.215 (30.86)	1.00 (25.4)	10.824 (274.93)	4.44 (2.01)
1½"	Sweat Female	46	2.41 (61.2)	9.16 (232.6)	4.923 (125.04)	3.12 (79.12)	2.72 (69)	1.815 (46.11)	4.227 (107.37)	5.16 (131)	2.82 (71.63)	1.41 (35.81)	1.23 (31.24)	12.432 (315.77)	7.25 (3.29)
1½"	NPT Female	46	1.83 (46.5)	8.58 (217.9)	4.923 (125.04)	3.12 (79.12)	2.72 (69)	1.815 (46.11)	4.227 (107.37)	5.16 (131)	2.82 (71.63)	1.41 (35.81)	1.250 (31.75)	12.452 (316.28)	7.25 (3.29)
2"	Sweat Female	54	2.943 (74.74)	10.16 (258.1)	5.368 (136.35)	3.72 (94.5)	2.961 (75.21)	1.897 (48.19)	4.441 (112.81)	6.58 (167.13)	3.5 (88.9)	1.75 (44.45)	1.48 (37.59)	14.398 (365.71)	10 (4.54)
2"	NPT Female	54	2.185 (55.5)	9.4 (238.8)	5.368 (136.35)	3.72 (94.5)	2.961 (75.21)	1.897 (48.19)	4.441 (112.81)	6.58 (167.13)	3.50 (88.9)	1.75 (44.45)	1.170 (29.72)	14.088 (357.84)	10 (4.54)

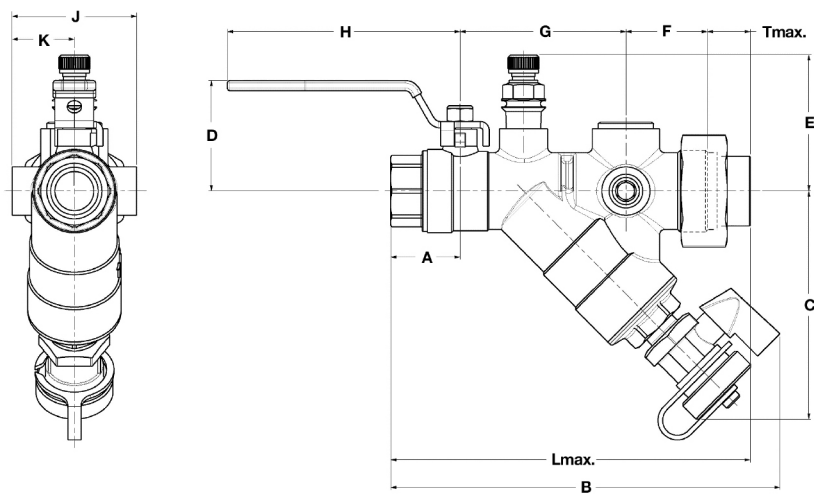

NOTE: THIS MODEL WILL BE SELECTED IF ADDITIONAL PT PORTS OR BYPASS IS REQUIRED.

Valve Size Fixed End	Connection Fixed End	Cv	DIMENSIONS* INCH (mm)												Approx. Weight Lbs. (kg)
			A	B	C	D	E	F	G	H	J	K	T (Max)	L (Max)	
½"	Sweat Female	4.1	1.303 (33.1)	6.162 (156.52)	3.447 (87.56)	1.672 (42.46)	2.060 (52.32)	1.238 (31.45)	2.518 (63.95)	3.533 (89.74)	1.890 (48)	0.945 (24)	0.600 (15.24)	5.659 (143.74)	1.5 (.68)
½"	NPT Female	4.1	1.055 (26.8)	5.914 (150.22)	3.447 (87.56)	1.672 (42.46)	2.060 (52.32)	1.238 (31.45)	2.518 (63.95)	3.533 (89.74)	1.890 (48)	0.945 (24)	0.650 (16.51)	5.461 (138.71)	1.5 (.68)
¾"	Sweat Female	6.8	1.559 (39.6)	6.733 (171.03)	3.670 (93.22)	1.819 (46.2)	2.114 (53.7)	1.220 (31)	2.827 (71.8)	3.533 (89.74)	2.126 (54)	1.063 (27)	0.850 (21.59)	6.456 (163.99)	1.81 (.82)
¾"	NPT Female	6.8	1.189 (30.2)	6.363 (161.63)	3.670 (93.22)	1.819 (46.2)	2.114 (53.7)	1.220 (31)	2.827 (71.8)	3.533 (89.74)	2.126 (54)	1.063 (27)	0.800 (20.32)	6.036 (153.32)	1.81 (.82)
1"	Sweat Female	8.8	1.846 (46.9)	7.933 (201.49)	4.519 (114.79)	2.224 (56.5)	2.323 (59)	1.772 (45)	3.520 (89.4)	4.290 (108.96)	2.480 (63)	1.240 (31.5)	1.010 (25.65)	8.148 (206.95)	3.06 (1.63)
1"	NPT Female	8.8	1.421 (36.1)	7.508 (190.69)	4.519 (114.79)	2.224 (56.5)	2.323 (59)	1.772 (45)	3.520 (89.4)	4.290 (108.96)	2.480 (63)	1.240 (31.5)	0.900 (22.86)	7.613 (193.36)	3.06 (1.63)
1¼"	Sweat Female	14	2.167 (55.03)	8.672 (220.27)	4.714 (119.74)	2.882 (73.2)	2.475 (62.87)	1.587 (40.3)	3.831 (97.3)	5.158 (131.02)	2.953 (75)	1.476 (37.5)	1.070 (27.18)	8.654 (219.81)	4.44 (2.01)
1¼"	NPT Female	14	1.634 (41.5)	8.139 (206.74)	4.714 (119.74)	2.882 (73.2)	2.475 (62.87)	1.587 (40.3)	3.831 (97.3)	5.158 (131.02)	2.953 (75)	1.476 (37.5)	1.000 (25.4)	8.051 (204.5)	4.44 (2.01)
1½"	Sweat Female	31	2.408 (61.17)	9.434 (239.61)	4.923 (125.04)	3.118 (79.2)	2.715 (68.96)	2.244 (57)	4.449 (113)	5.158 (131.02)	3.307 (84)	1.654 (42)	1.230 (31.24)	10.331 (262.41)	7.25 (3.29)
1½"	NPT Female	31	1.831 (46.5)	8.856 (224.94)	4.923 (125.04)	3.118 (79.2)	2.715 (68.96)	2.24 (57.0)	4.449 (113)	5.158 (131.02)	3.307 (84)	1.654 (42)	1.250 (31.75)	9.774 (248.25)	7.25 (3.29)
2"	Sweat Female	34	2.943 (74.74)	10.630 (270)	5.368 (136.35)	3.602 (91.5)	2.961 (75.21)	2.087 (53)	5.098 (129.5)	6.580 (167.13)	3.977 (101.01)	1.988 (50.5)	1.480 (37.59)	11.608 (294.83)	10 (4.54)
2"	NPT Female	34	2.185 (55.5)	9.872 (250.76)	5.368 (136.35)	3.602 (91.5)	2.961 (75.21)	2.087 (53)	5.098 (129.5)	6.580 (167.13)	3.977 (101.01)	1.988 (50.5)	1.170 (29.72)	10.540 (267.72)	10 (4.54)