

DG900DB

CDMA/GSM DUAL BAND ANTENNA

This Antenna is ideal for trunking and SMR applications. It is ground independent and particularly suited for mounting to control cabinet applications. Internal or external applications.

BANDWIDTH: 820-960 MHz 1800MHz

MOUNTING: 12.7mm bottom bolt with optional angle mounting bracket (as shown) to suit

ELECTRICAL SPECIFICATIONS

Power	50 Watts
Termination	Opt. BNC/SMA/FME on RG58/RG174 cable tail
VSWR (see graph below)	< 1.5:1 over tuned bandwidth


Cable tail lengths can be changed on request

Ground independent Y

Gain 3.5 dbi

MECHANICAL SPECIFICATIONS

Height	160 mm
Construction	UVPVC & Brass
Mounting Bracket (SS)	Optional extra
Radiator	Copper

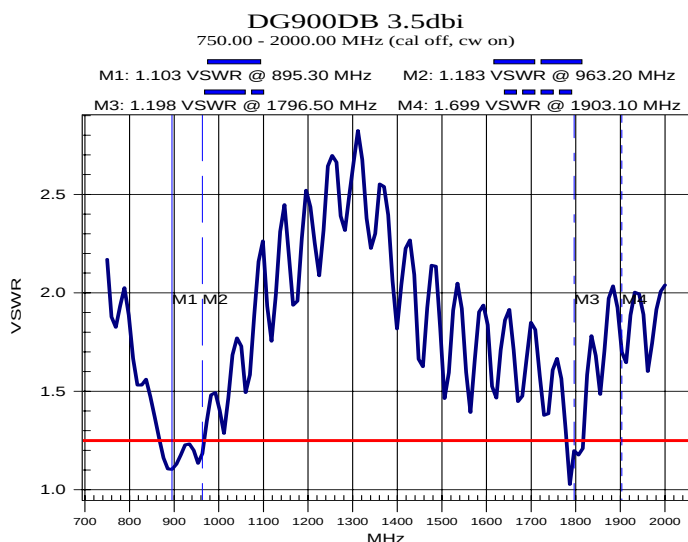

D & G ANTENNAS

6 Elliott Street, KINGSWOOD NSW 2747 PH/FAX: 02 4732 3083
MOBILE: 0408 960 770 EMAIL: dg_antennas@iprimus.com.au