


6BF (2 & 4 pole) Performance Comparison

CURVE / C6BFPERF




3500 RPM - 2 POLE

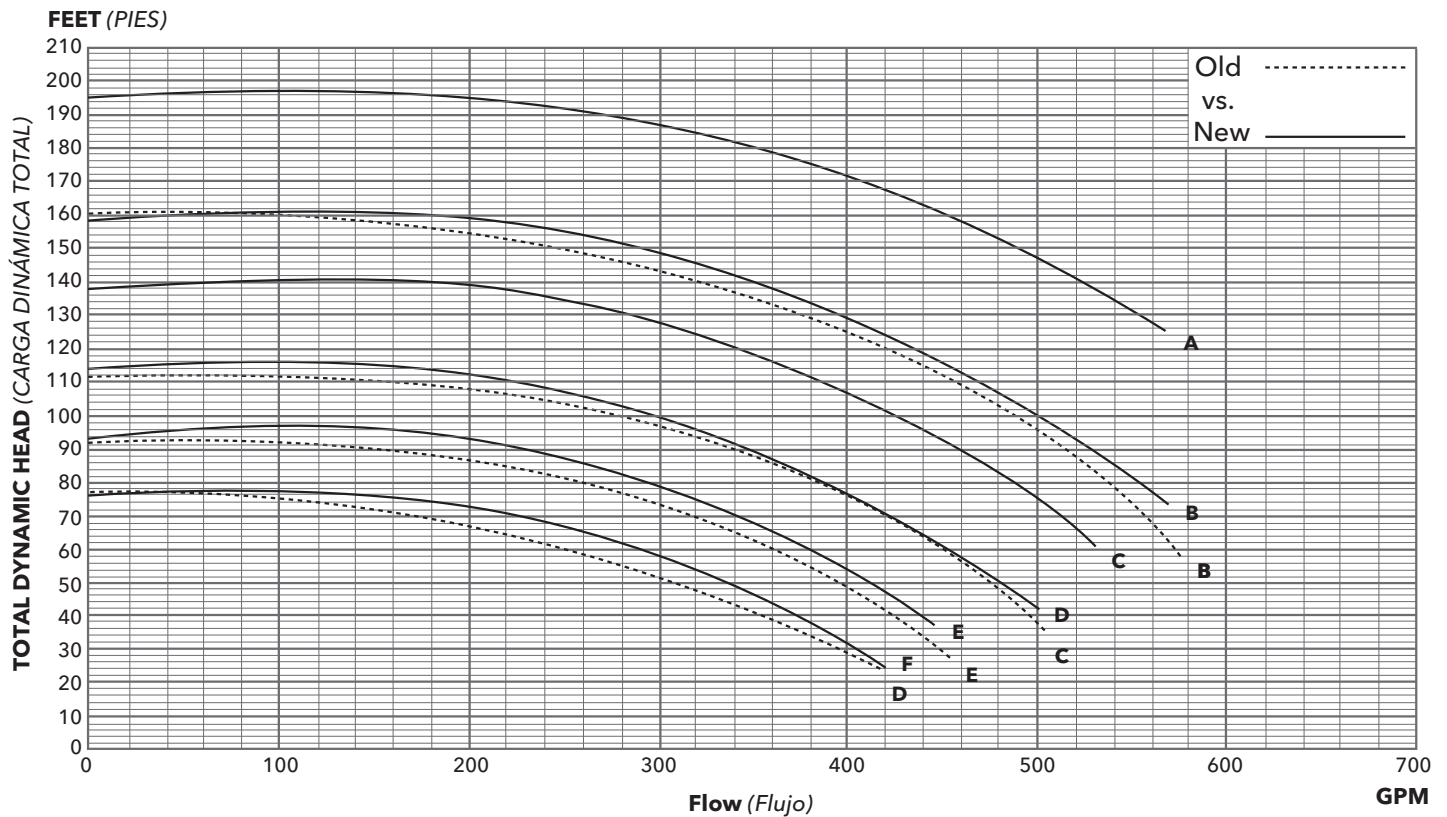

Previous Impeller	Previous Impeller Dia. (in)	New Impeller	New Impeller Dia. (in)
		A	7.06
B	6.38	B	6.38
C	5.50	C	6.00
D	4.69	D	5.50
E	5.12	E	5.12
		F	4.69

1750 RPM - 4 POLE

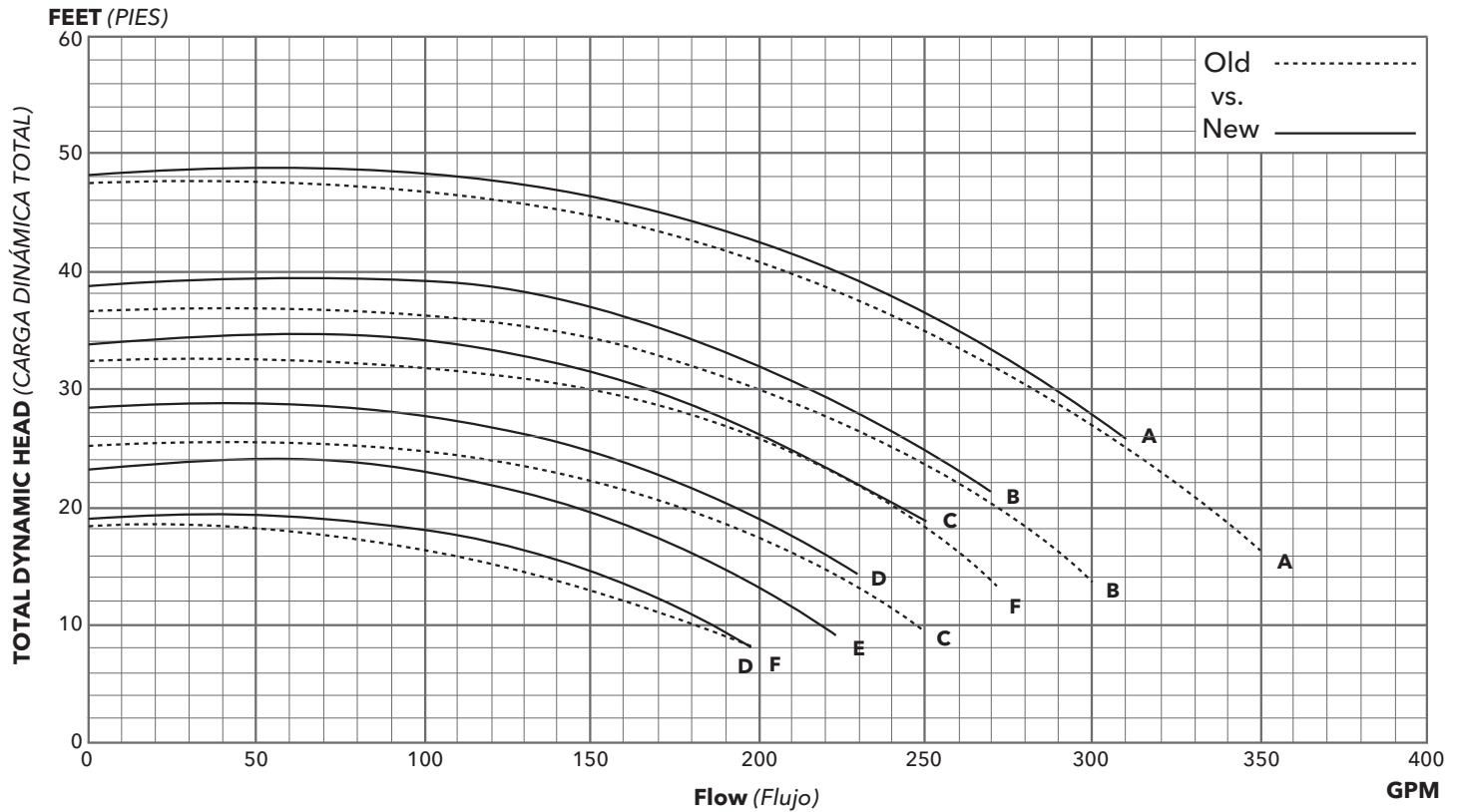

Previous Impeller	Previous Impeller Dia. (in)	New Impeller	New Impeller Dia. (in)
A	7.06	A	7.06
B	6.38	B	6.38
C	5.50	C	6.00
D	4.69	D	5.50
		E	5.12
F	6.00	F	4.69

Xylem Inc.

2881 East Bayard Street Ext., Suite A, Seneca Falls, NY 13148

Phone: (866) 673-0428 Fax: (888) 322-5877

www.xylem.com/goulds

Goulds is a registered trademark of Goulds Pumps, Inc. and is used under license.

© 2020 Xylem Inc. C6BFPERF February 2020

