


125MC Performance Comparison

CURVE / C125MCPERF

125MC 3500 RPM – 2 POLE

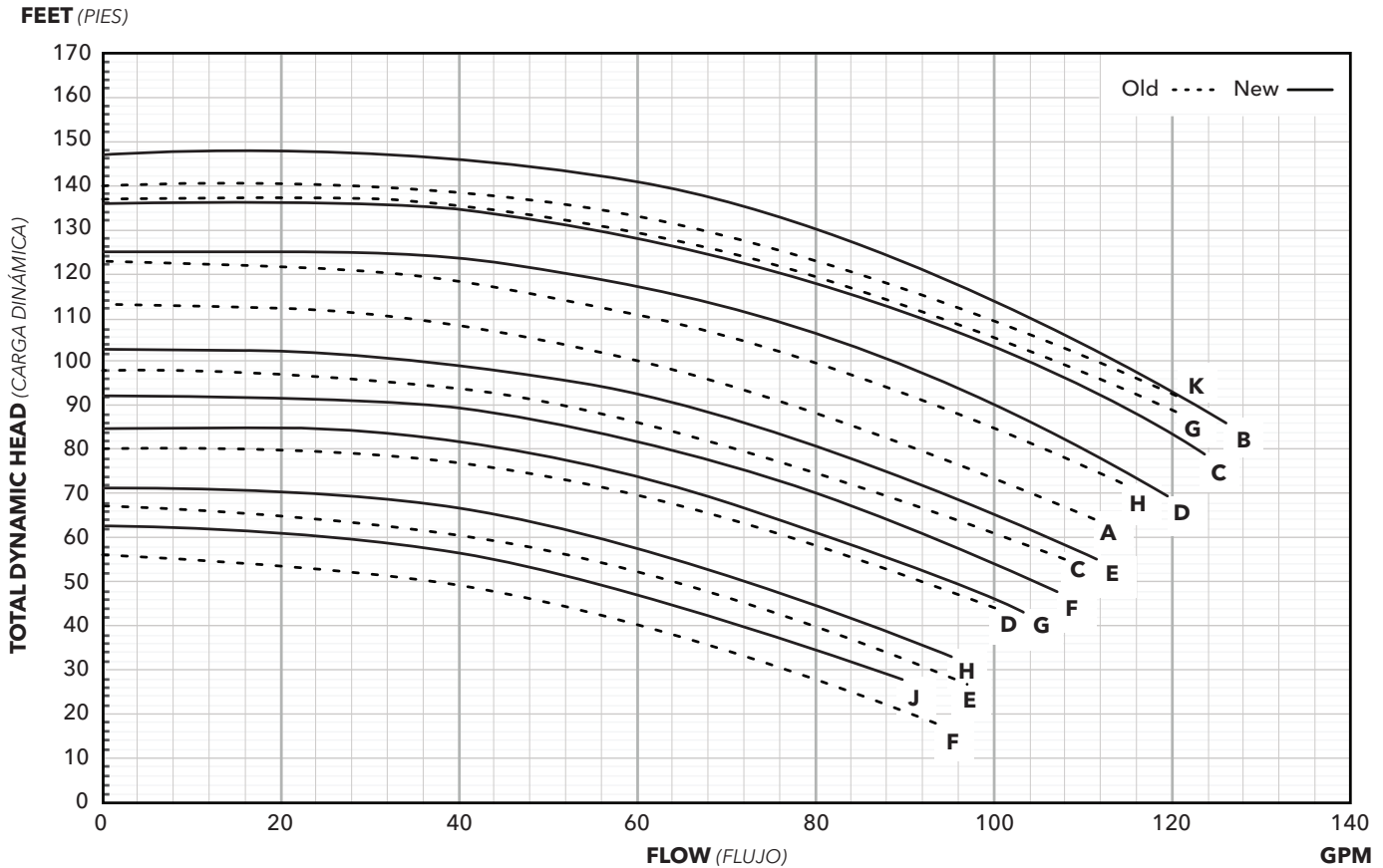

Previous Impeller		New Impeller	
2MC Impellers		125MC Impellers	
Code	Dia. (in)	Code	Dia. (in)
A	5.25	—	—
B	5.06	B	5.94
C	4.88	C	5.75
D	4.63	D	5.34
E	4.25	E	5.06
F	3.88	F	4.88
G	5.94	G	4.63
H	5.50	H	4.25
—	—	J	4.00