


150MC

Performance Comparison

CURVE / C150MCPERF

150MC 3500 RPM – 2 POLE

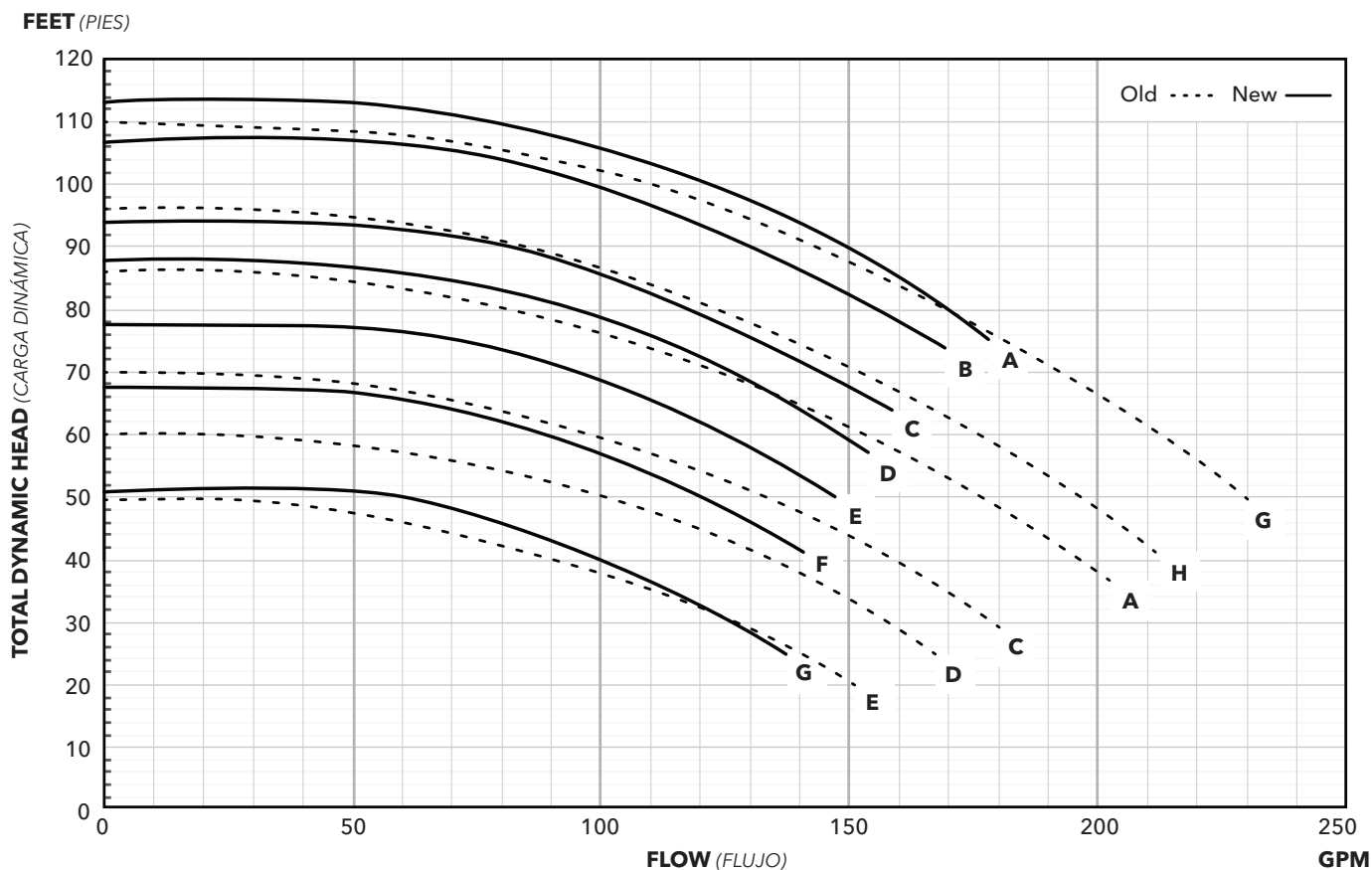

Previous Impeller		New Impeller	
3MC Impellers		150MC Impellers	
Code	Dia. (in)	Code	Dia. (in)
A	4.75	A	5.13
B	4.63	B	5.00
C	4.38	C	4.75
D	4.06	D	4.50
E	3.63	E	4.38
F	—	F	4.00
G	5.38	G	3.63
H	5.00	—	—