


2MS (2 & 4 pole) Performance Comparison

CURVE / C2MSPERF




3500 RPM - 2 POLE

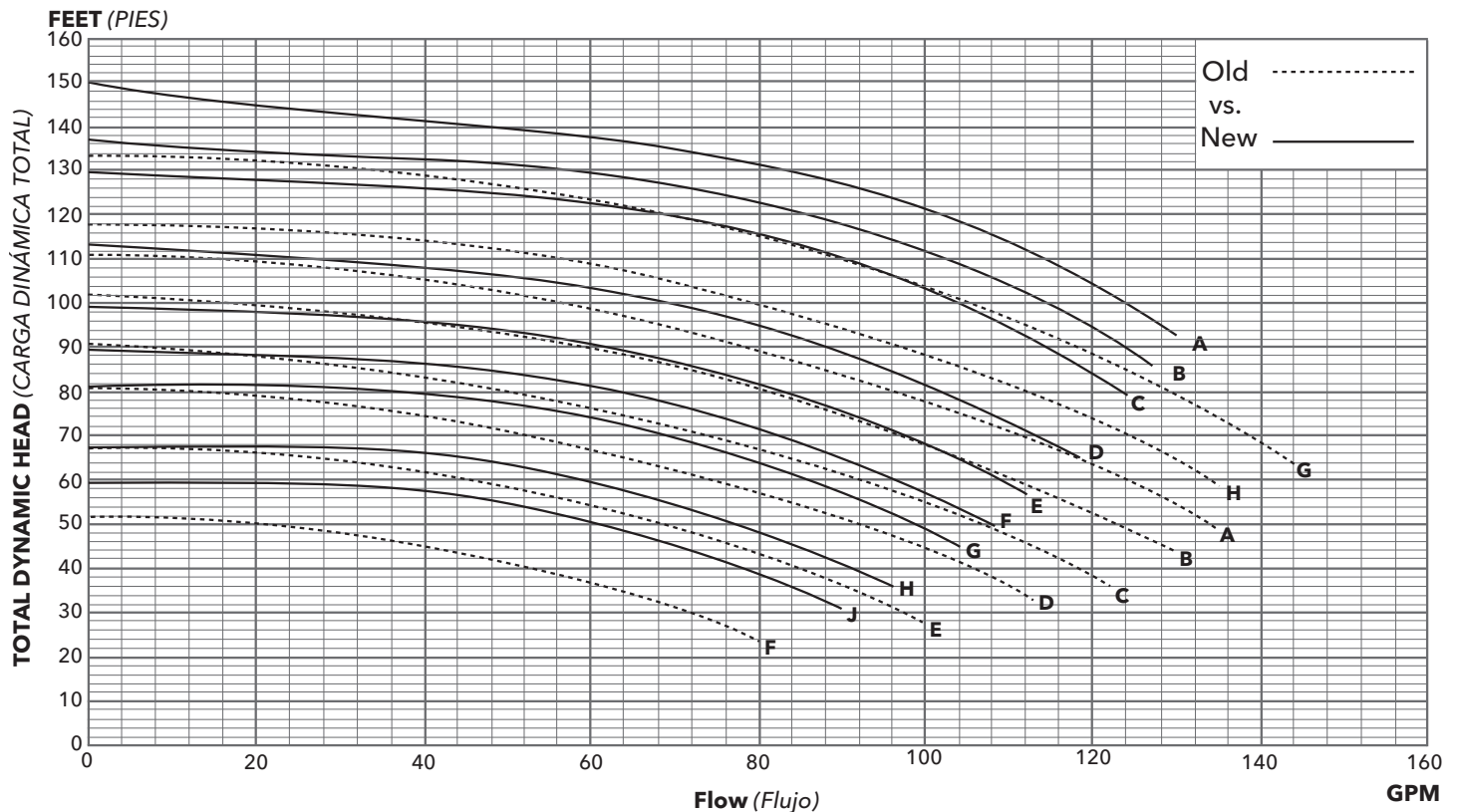

Previous Impeller	Previous Impeller Dia. (in)	New Impeller	New Impeller Dia. (in)
G	5.94		
H	5.50		
A	5.25	A	6.13
B	5.06	B	5.94
C	4.88	C	5.75
D	4.63	D	5.34
E	4.25	E	5.06
F	3.88	F	4.88
		G	4.63
		H	4.25
		J	4.00

1750 RPM - 4 POLE

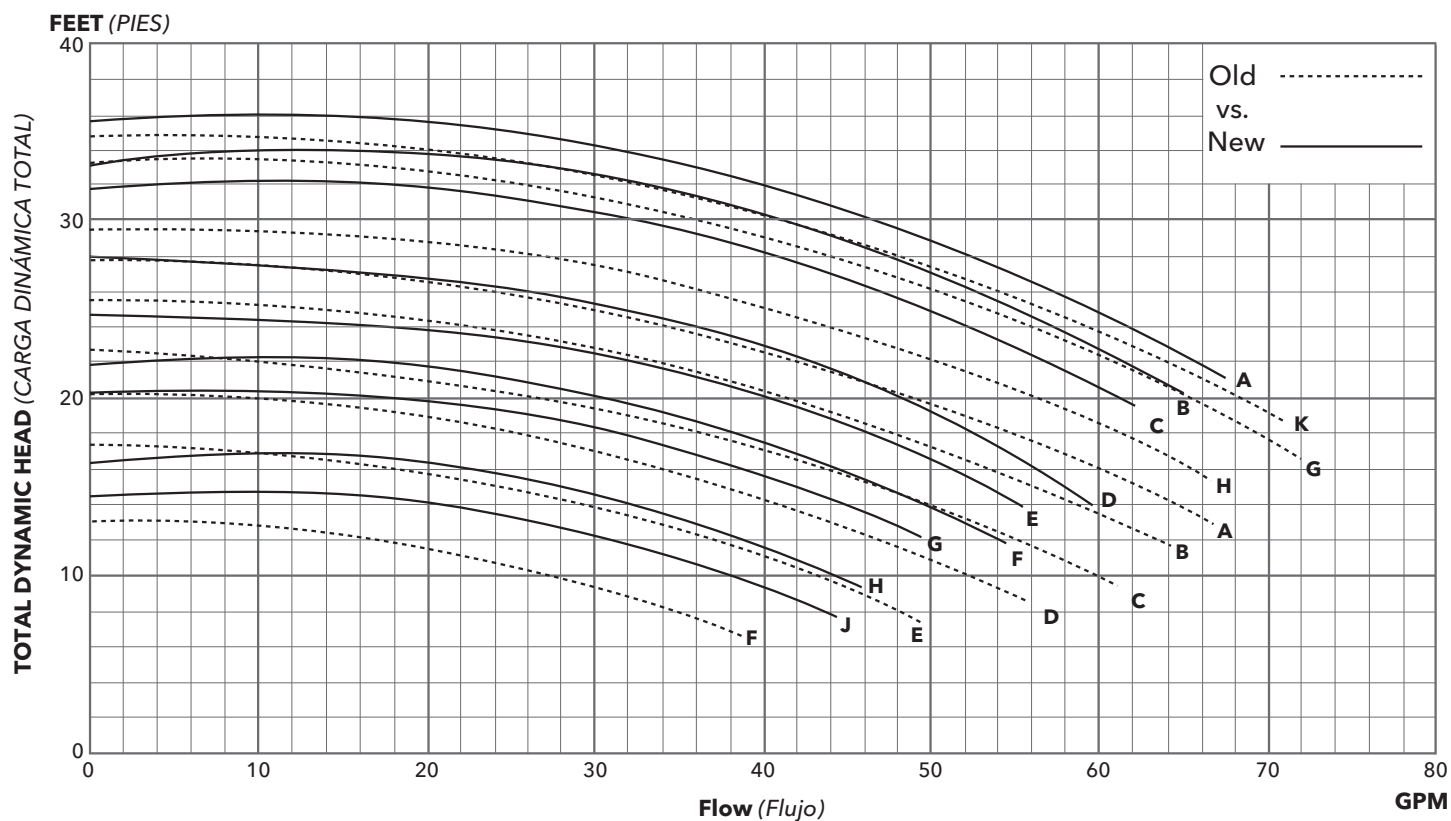

Previous Impeller	Previous Impeller Dia. (in)	New Impeller	New Impeller Dia. (in)
K	6.12		
G	5.94	G	4.63
H	5.50	H	4.25
		J	4.00
A	5.25	A	6.13
B	5.06	B	5.94
C	4.88	C	5.75
D	4.63	D	5.34
E	4.25	E	5.06
F	3.88	F	4.88

Xylem Inc.

2881 East Bayard Street Ext., Suite A, Seneca Falls, NY 13148

Phone: (866) 673-0428 Fax: (888) 322-5877

www.xylem.com/goulds

Goulds is a registered trademark of Goulds Pumps, Inc. and is used under license.

© 2020 Xylem Inc. C2MSPERF March 2020

