


3MS (2 & 4 pole) Performance Comparison

CURVE / C3MSPERF




3500 RPM - 2 POLE

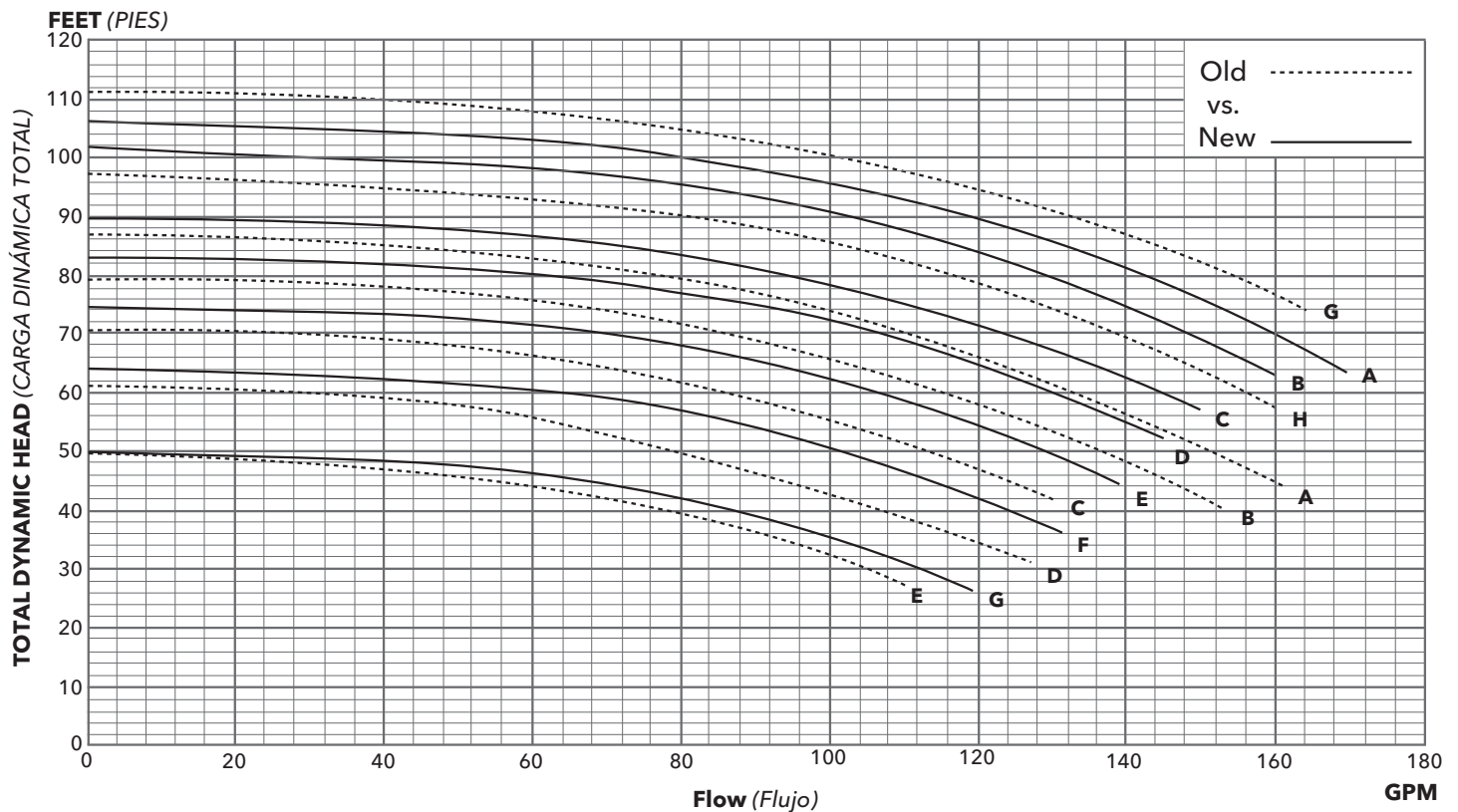

Previous Impeller	Previous Impeller Dia. (in)	New Impeller	New Impeller Dia. (in)
A	4.75	A	5.13
B	4.63	B	5.00
C	4.38	C	4.75
D	4.06	D	4.50
E	3.63	E	4.38
F		F	4.06
G	5.38	G	3.63
H	5.00		

1750 RPM - 4 POLE

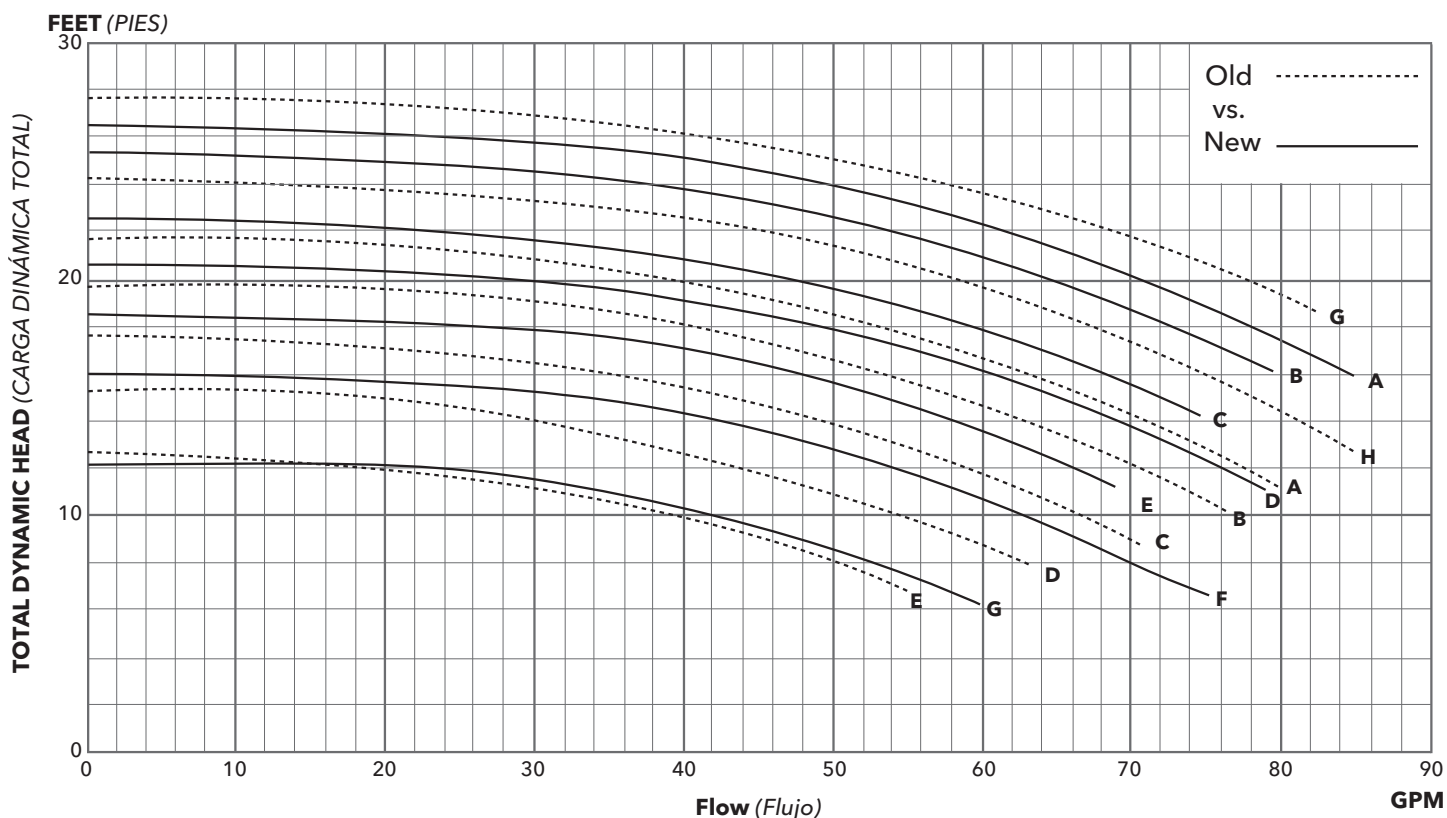

Previous Impeller	Previous Impeller Dia. (in)	New Impeller	New Impeller Dia. (in)
A	4.75	A	5.13
B	4.63	B	5.00
C	4.38	C	4.75
D	4.06	D	4.50
E	3.63	E	4.38
F		F	4.06
G	5.38	G	3.63
H	5.00		

Xylem Inc.

2881 East Bayard Street Ext., Suite A, Seneca Falls, NY 13148

Phone: (866) 673-0428 Fax: (888) 322-5877

www.xylem.com/goulds

Goulds is a registered trademark of Goulds Pumps, Inc. and is used under license.

© 2020 Xylem Inc. C3MSPERF March 2020

