


JOB: UNIT TAG: ENGINEER: CONTRACTOR:	REPRESENTATIVE: ORDER NO. SUBMITTED BY: APPROVED BY:	DATE: DATE: DATE:
---	---	--

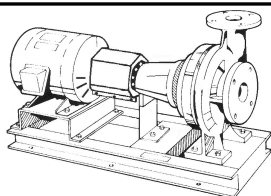

3-9D

Marlow Series e-530SL

Centrifugal Pumps - Base Mounted

SPECIFICATIONS

FLOW _____ HEAD _____
 HP _____ RPM _____
 VOLTS _____
 CYCLE _____ PHASE _____
 ENCLOSURE _____
 APPROX. WEIGHT _____
 SPECIALS _____

MATERIALS OF CONSTRUCTION

☒ Stainless Steel Fitted

FEATURES

- ☒ ANSI/OSHA Coupling Guard
- ☒ Center Drop Out Spacer Coupling
- ☒ Fabricated Heavy Duty Baseplate


MAXIMUM WORKING PRESSURE

- ☐ 175 psi (12 bar) W.P.
w/ 125# ANSI flange drilling


TYPE OF SEAL

- ☐ Standard Seal
(Buna-Carbon/Ceramic)
- ☐ -F Standard Seal w/ Flush Line
(Buna-Carbon/Ceramic)
- ☐ -S Stuffing Box Construction w/ Flushed
Mechanical Single Seal
(EPR-Tungsten Carbide/Carbon)
- ☐ -PF Stuffing Box Construction w/ Packing
(Graphite Impregnated Teflon)

Note: Equipped with NEOPRENE coupling

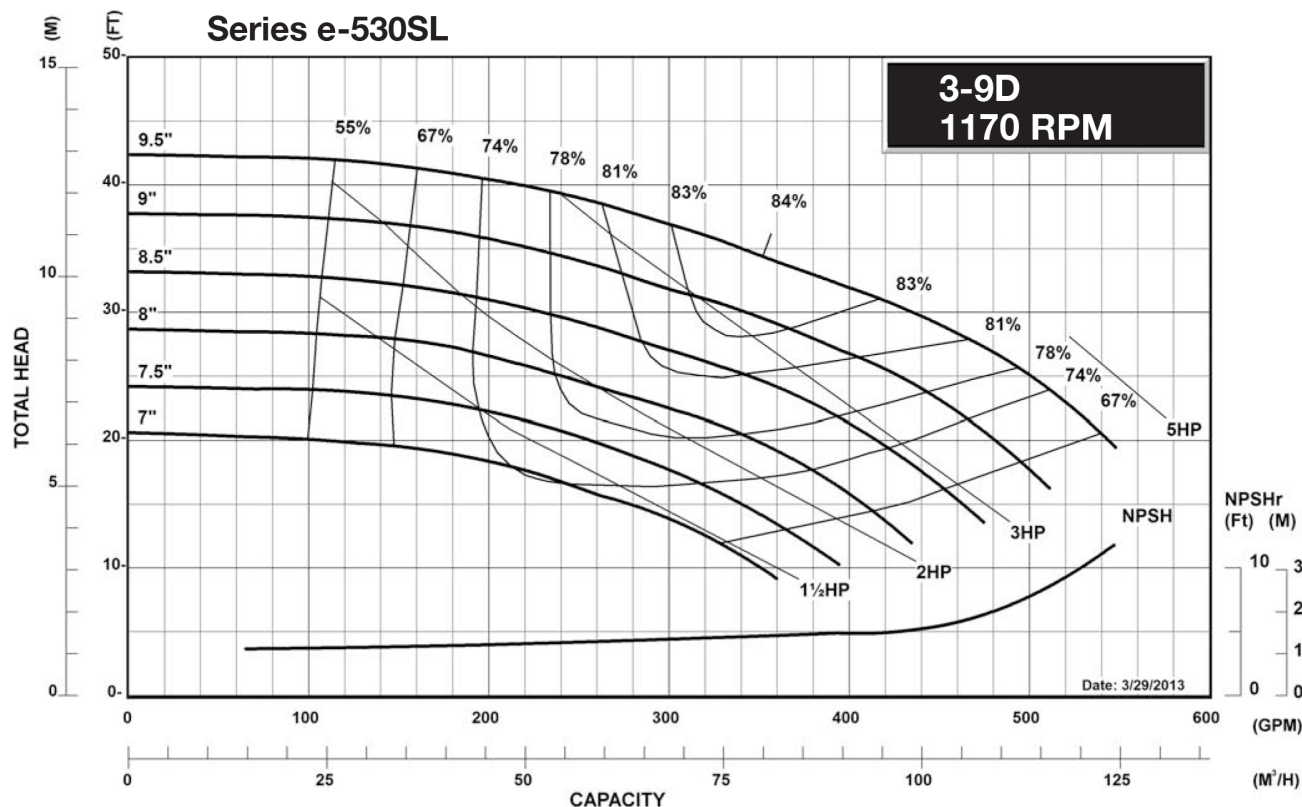

JOB: UNIT TAG: ENGINEER: CONTRACTOR:	REPRESENTATIVE: ORDER NO.: SUBMITTED BY: APPROVED BY:	DATE: DATE: DATE:
---	--	--

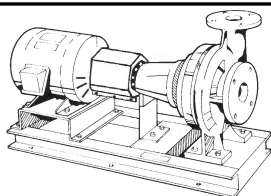

3-9D Marlow Series e-530SL Centrifugal Pumps - Base Mounted

SPECIFICATIONS

FLOW _____	HEAD _____
HP _____	RPM _____
VOLTS _____	
CYCLE _____	PHASE _____
ENCLOSURE _____	
APPROX. WEIGHT _____	
SPECIALS _____	

MATERIALS OF CONSTRUCTION

☒ Stainless Steel Fitted

FEATURES

- ☒ ANSI/OSHA Coupling Guard
- ☒ Center Drop Out Spacer Coupling
- ☒ Fabricated Heavy Duty Baseplate


MAXIMUM WORKING PRESSURE

- ☐ 175 psi (12 bar) W.P.
w/ 125# ANSI flange drilling


TYPE OF SEAL

- ☐ Standard Seal
(Buna-Carbon/Ceramic)
- ☐ -F Standard Seal w/ Flush Line
(Buna-Carbon/Ceramic)
- ☐ -S Stuffing Box Construction w/ Flushed
Mechanical Single Seal
(EPR-Tungsten Carbide/Carbon)
- ☐ -PF Stuffing Box Construction w/ Packing
(Graphite Impregnated Teflon)

Note: Equipped with NEOPRENE coupling

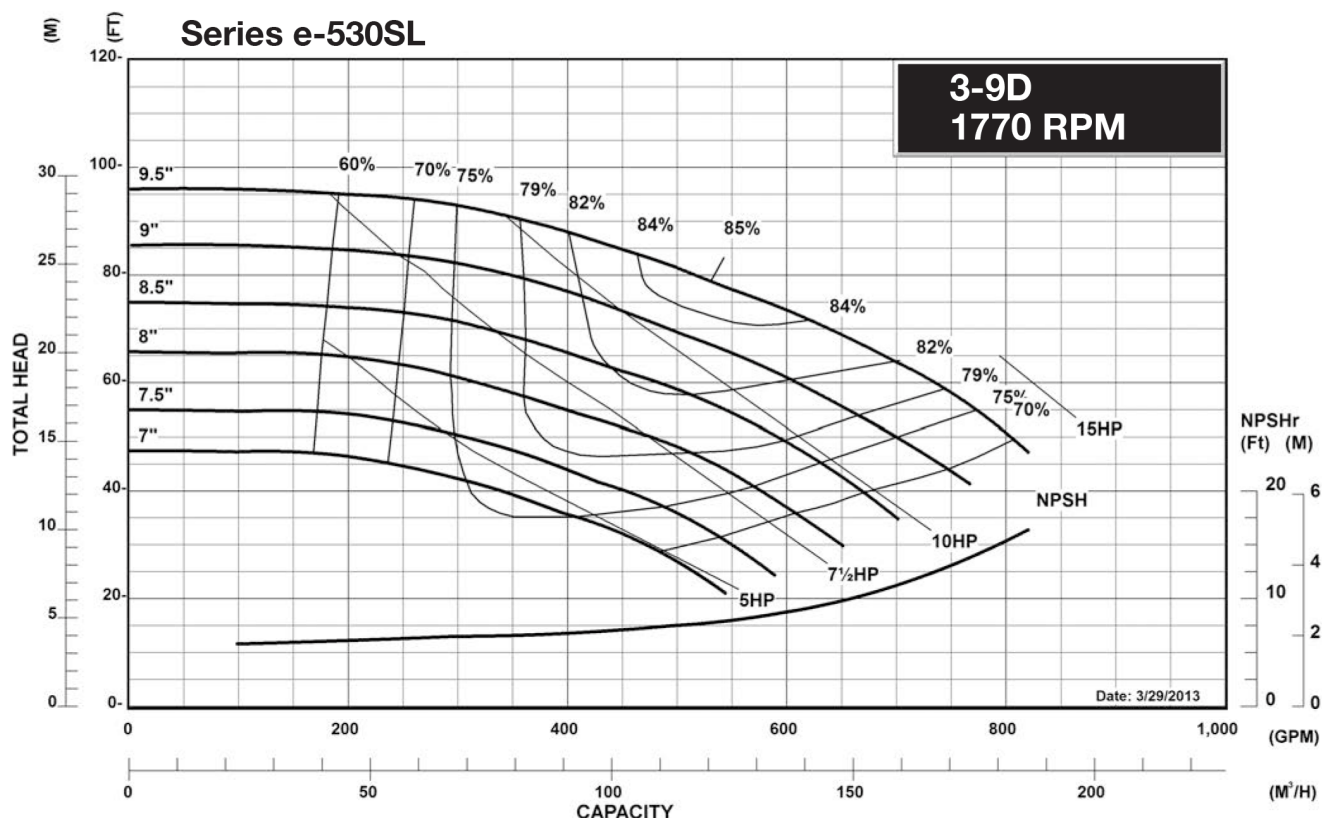

JOB: UNIT TAG: ENGINEER: CONTRACTOR:	REPRESENTATIVE: ORDER NO. SUBMITTED BY: APPROVED BY:	DATE: DATE: DATE:
---	---	--

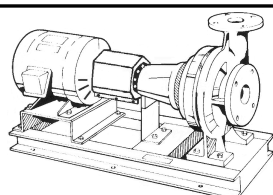

3-9D Marlow Series e-530SL Centrifugal Pumps - Base Mounted

SPECIFICATIONS

FLOW _____	HEAD _____
HP _____	RPM _____
VOLTS _____	
CYCLE _____	PHASE _____
ENCLOSURE _____	
APPROX. WEIGHT _____	
SPECIALS _____	

MATERIALS OF CONSTRUCTION

☒ Stainless Steel Fitted

FEATURES

- ☒ ANSI/OSHA Coupling Guard
- ☒ Center Drop Out Spacer Coupling
- ☒ Fabricated Heavy Duty Baseplate


MAXIMUM WORKING PRESSURE

- ☐ 175 psi (12 bar) W.P.
w/ 125# ANSI flange drilling

TYPE OF SEAL


- ☐ Standard Seal
(Buna-Carbon/Ceramic)
- ☐ -F Standard Seal w/ Flush Line
(Buna-Carbon/Ceramic)
- ☐ -S Stuffing Box Construction w/ Flushed
Mechanical Single Seal
(EPR-Tungsten Carbide/Carbon)
- ☐ -PF Stuffing Box Construction w/ Packing
(Graphite Impregnated Teflon)

Note: Equipped with NEOPRENE coupling

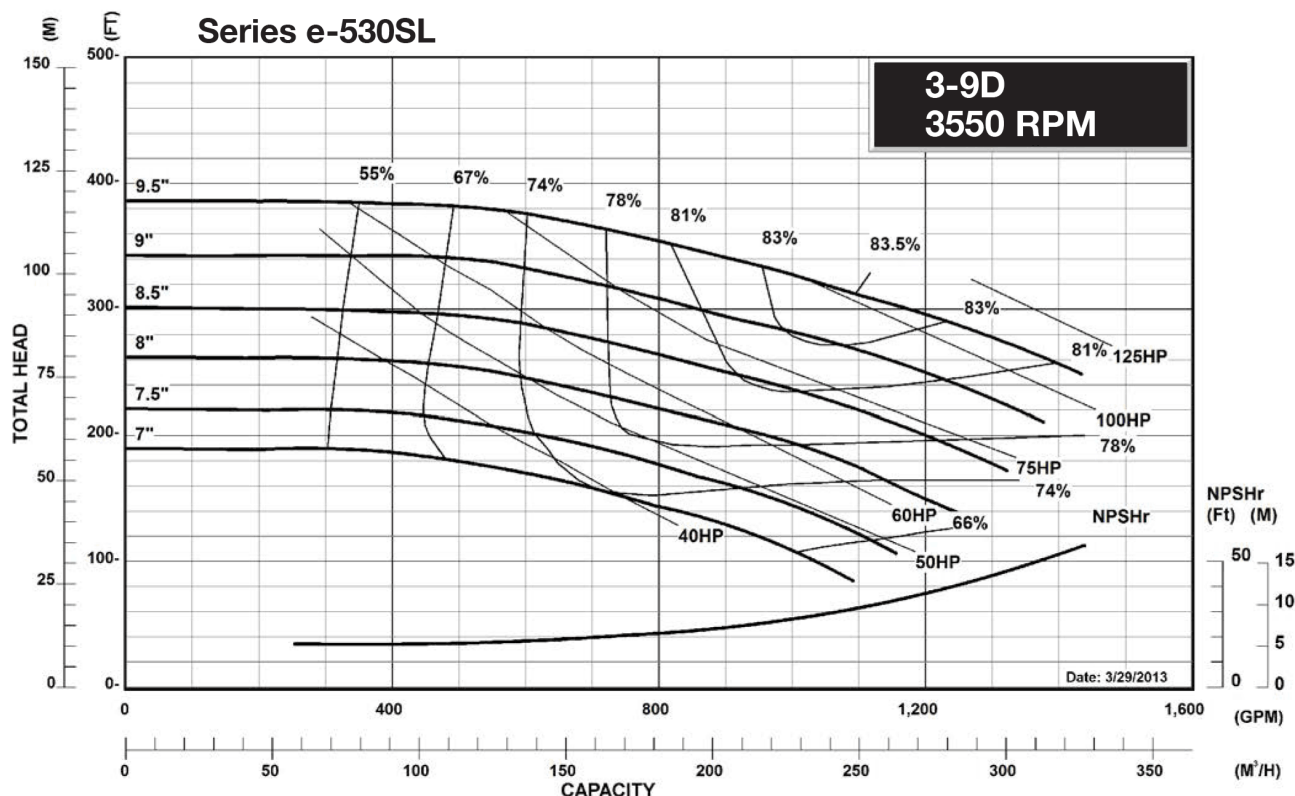

Marlow Series e-530SL 3-9D Centrifugal Pump Submittal

M-501.22

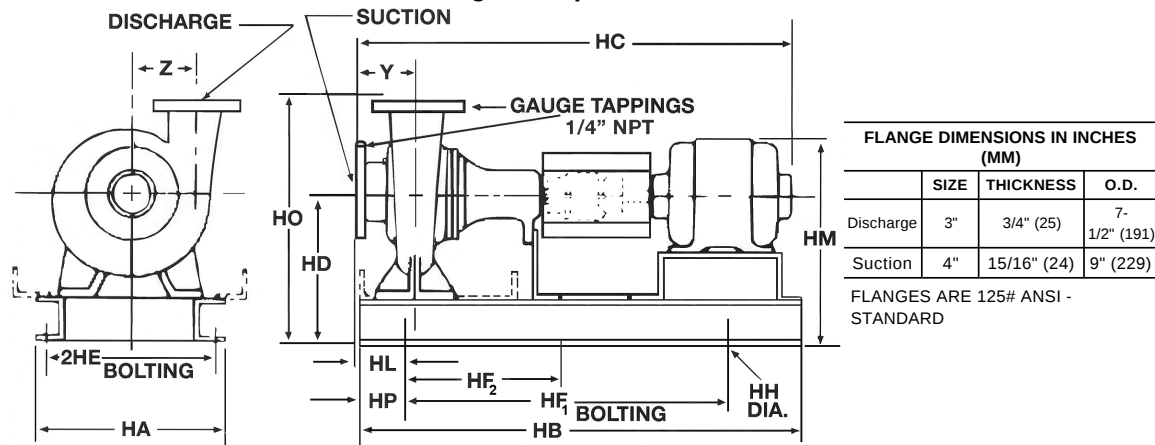

DIMENSIONS – Inches (mm)

STANDARD SEAL

MOTOR FRAME	HA	HB	HC MAX	HD	2HE	HF ₁	HF ₂	HH	HL	HM MAX	HO	HP	Y	Z
"S" FRAME														
182T	14-5/8 (371)	31 (787)	34-7/8 (886)	10-3/4 (273)	12-7/8 (327)	25 (635)	-	3/4 (19)	3-11/16 (94)	16 (406)	18-1/4 (464)	3 (76)	4-3/4 (121)	6-1/8 (156)
184T	14-5/8 (371)	31 (787)	34-7/8 (886)	10-3/4 (273)	12-7/8 (327)	25 (635)	-	3/4 (19)	3-11/16 (94)	16 (406)	18-1/4 (464)	3 (76)	4-3/4 (121)	6-1/8 (156)
213T	14-5/8 (371)	34-5/8 (879)	37-1/2 (953)	10-3/4 (273)	12-7/8 (327)	28-5/8 (727)	-	3/4 (19)	3-11/16 (94)	16-5/8 (422)	18-1/4 (464)	3 (76)	4-3/4 (121)	6-1/8 (156)
215T	14-5/8 (371)	34-5/8 (879)	39 (991)	10-3/4 (273)	12-7/8 (327)	28-5/8 (727)	-	3/4 (19)	3-11/16 (94)	16-5/8 (422)	18-1/4 (464)	3 (76)	4-3/4 (121)	6-1/8 (156)
254T	14-5/8 (371)	39-3/8 (1000)	42-3/4 (1086)	10-3/4 (273)	12-7/8 (327)	33-3/8 (848)	-	3/4 (19)	3-11/16 (94)	17-5/8 (448)	18-1/4 (464)	3 (76)	4-3/4 (121)	6-1/8 (156)
"L" FRAME														
284TS	16 (406)	46-1/2 (1181)	48-1/8 (1222)	13 (330)	14 (356)	36-1/2 (927)	18-1/4 (464)	7/8 (22)	4-13/16 (122)	21 (533)	20-1/2 (521)	5 (127)	4-3/4 (121)	6-1/8 (156)
286TS	16 (406)	46-1/2 (1181)	49-5/8 (1260)	13 (330)	14 (356)	36-1/2 (927)	18-1/4 (464)	7/8 (22)	4-13/16 (122)	21 (533)	20-1/2 (521)	5 (127)	4-3/4 (121)	6-1/8 (156)
324TS	16 (406)	46-1/2 (1181)	51-1/2 (1308)	12 (305)	14 (356)	36-1/2 (927)	18-1/4 (464)	7/8 (22)	4-13/16 (122)	21 (533)	19-1/2 (495)	5 (127)	4-3/4 (121)	6-1/8 (156)
326TS	16 (406)	46-1/2 (1181)	53 (1346)	12 (305)	14 (356)	36-1/2 (927)	18-1/4 (464)	7/8 (22)	4-13/16 (122)	21 (533)	19-1/2 (495)	5 (127)	4-3/4 (121)	6-1/8 (156)
364TS	16 (406)	51-3/4 (1314)	53-1/2 (1359)	13-1/4 (337)	14 (356)	41-3/4 (1060)	20-7/8 (530)	7/8 (22)	4-13/16 (122)	22-1/2 (572)	20-3/4 (527)	5 (127)	4-3/4 (121)	6-1/8 (156)
365TS	16 (406)	51-3/4 (1314)	55 (1397)	13-1/4 (337)	14 (356)	41-3/4 (1060)	20-7/8 (530)	7/8 (22)	4-13/16 (122)	22-1/2 (572)	20-3/4 (527)	5 (127)	4-3/4 (121)	6-1/8 (156)

STUFFING BOX

MOTOR FRAME	HA	HB	HC MAX	HD	2HE	HF ₁	HF ₂	HH	HL	HM MAX	HO	HP	Y	Z
"S" FRAME														
182T	14-5/8 (371)	34-5/8 (879)	34-3/4 (959)	10-3/4 (273)	12-7/8 (327)	28-5/8 (727)	-	3/4 (19)	3-11/16 (93)	16 (406)	18-1/4 (464)	3 (76)	4-3/4 (121)	6-1/8 (156)
184T	14-5/8 (371)	34-5/8 (879)	38-1/2 (978)	10-3/4 (273)	12-7/8 (327)	28-5/8 (727)	-	3/4 (19)	3-11/16 (93)	16 (406)	18-1/4 (464)	3 (76)	4-3/4 (121)	6-1/8 (156)
213T	14-5/8 (371)	39-3/8 (1000)	41 (1041)	10-3/4 (273)	12-7/8 (327)	33-3/8 (848)	-	3/4 (19)	3-11/16 (93)	16-5/8 (422)	18-1/4 (464)	3 (76)	4-3/4 (121)	6-1/8 (156)
215T	14-5/8 (371)	39-3/8 (1000)	42-1/2 (1080)	10-3/4 (273)	12-7/8 (327)	33-3/8 (848)	-	3/4 (19)	3-11/16 (93)	16-5/8 (422)	18-1/4 (464)	3 (76)	4-3/4 (121)	6-1/8 (156)
254T	16 (406)	46-1/2 (1181)	46-1/4 (1175)	12 (305)	14 (356)	36-1/2 (927)	18-1/4 (464)	7/8 (22)	4-13/16 (122)	18-7/8 (479)	19-1/2 (495)	5 (127)	4-3/4 (121)	6-1/8 (156)
"L" FRAME														
284TS	16 (406)	51-3/4 (1314)	50-1/2 (1283)	13 (330)	14 (356)	41-3/4 (1060)	20-7/8 (530)	7/8 (22)	4-13/16 (122)	21 (533)	20-1/2 (521)	5 (127)	4-3/4 (121)	6-1/8 (156)
286TS	16 (406)	51-3/4 (1314)	52 (1321)	13 (330)	14 (356)	41-3/4 (1060)	20-7/8 (530)	7/8 (22)	4-13/16 (122)	21 (533)	20-1/2 (521)	5 (127)	4-3/4 (121)	6-1/8 (156)
324TS	16 (406)	51-3/4 (1314)	54 (1372)	12 (305)	14 (356)	41-3/4 (1060)	20-7/8 (530)	7/8 (22)	4-13/16 (122)	21 (533)	19-1/2 (495)	5 (127)	4-3/4 (121)	6-1/8 (156)
326TS	16 (406)	51-3/4 (1314)	55-1/2 (1410)	12 (305)	14 (356)	41-3/4 (1060)	20-7/8 (530)	7/8 (22)	4-13/16 (122)	21 (533)	19-1/2 (495)	5 (127)	4-3/4 (121)	6-1/8 (156)

Dimensions are subject to change. Not to be used for construction purposes unless certified.

Xylem Inc.
8200 N. Austin Avenue
Morton Grove, IL 60053
Phone: (847)966-3700
Fax: (847)965-8379
www.gouldswatertechnology.com

Goulds is a registered trademark of Goulds Pumps, Inc. and is used under license.
© 2016 Xylem Inc.

xylem
Let's Solve Water