


JOB:	REPRESENTATIVE:	
UNIT TAG:	ORDER NO.	DATE:
ENGINEER:	SUBMITTED BY:	DATE:
CONTRACTOR:	APPROVED BY:	DATE:

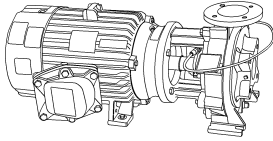

Marlow Commercial Pool Pumps

Marlow Series 530, Model 8-13SC

Centrifugal Pumps - Closed-Coupled

SPECIFICATIONS

FLOW	_____	HEAD	_____
HP	_____	RPM	_____
VOLTS	_____		
CYCLE	_____	PHASE	_____
ENCLOSURE	_____		
APPROX. WEIGHT	_____		
SPECIALS	_____		

MATERIALS OF CONSTRUCTION


☐ BRONZE FITTED

MAXIMUM WORKING PRESSURE


☐ 175 psi (12 bar) W.P.
with 125# ANSI flange drilling
(Max. Suction Pressure 75 psi [5.2 bar])

TYPE OF SEAL

- ☐ 530 -S, Stuffing Box Construction
w/ Flushed Single Mechanical Seal
EPR-Carbon NiResist
Max 250°F[120°C]
- ☐ 530 -S, Stuffing Box Construction
w/ Flushed Single Mechanical Seal
EPR-Carbon/Tungsten Carbide
Max 250°F[120°C]
- ☐ 530 -S, Stuffing Box Construction
w/ Flushed Mechanical Seal
Buna-Carbon/Ceramic
Max 225°F[106°C]

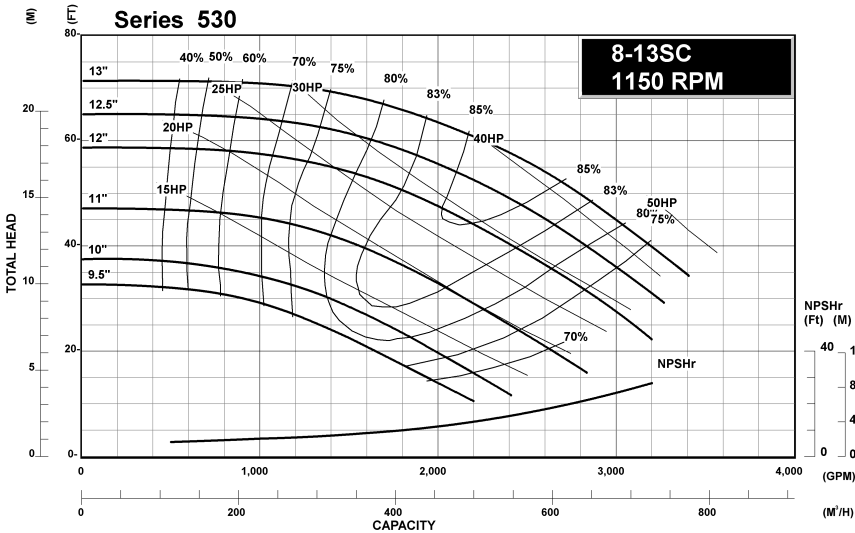

JOB:	REPRESENTATIVE:		
UNIT TAG:	ORDER NO.	DATE:	
ENGINEER:	SUBMITTED BY:	DATE:	
CONTRACTOR:	APPROVED BY:	DATE:	

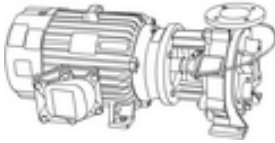

Marlow Commercial Pool Pumps

Marlow Series 530, Model 8-13SC

Centrifugal Pumps - Closed-Coupled

SPECIFICATIONS

FLOW	_____	HEAD	_____
HP	_____	RPM	_____
VOLTS	_____		
CYCLE	_____	PHASE	_____
ENCLOSURE	_____		
APPROX. WEIGHT	_____		
SPECIALS	_____		

MATERIALS OF CONSTRUCTION


☐ BRONZE FITTED


MAXIMUM WORKING PRESSURE

☐ 175 psi (12 bar) W.P.
with 125# ANSI flange drilling
(Max. Suction Pressure 75 psi [5.2 bar])

TYPE OF SEAL

- ☐ 530 -S, Stuffing Box Construction
w/ Flushed Single Mechanical Seal
EPR-Carbon NiResist
Max 250°F[120°C]
- ☐ 530 -S, Stuffing Box Construction
w/ Flushed Single Mechanical Seal
EPR-Carbon/Tungsten Carbide
Max 250°F[120°C]
- ☐ 530 -S, Stuffing Box Construction
w/ Flushed Mechanical Seal
Buna-Carbon/Ceramic
Max 225°F[106°C]

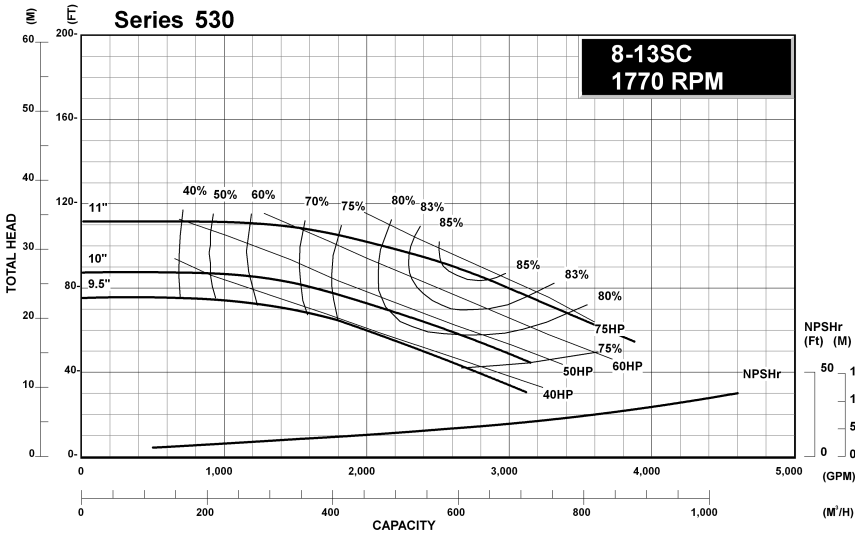

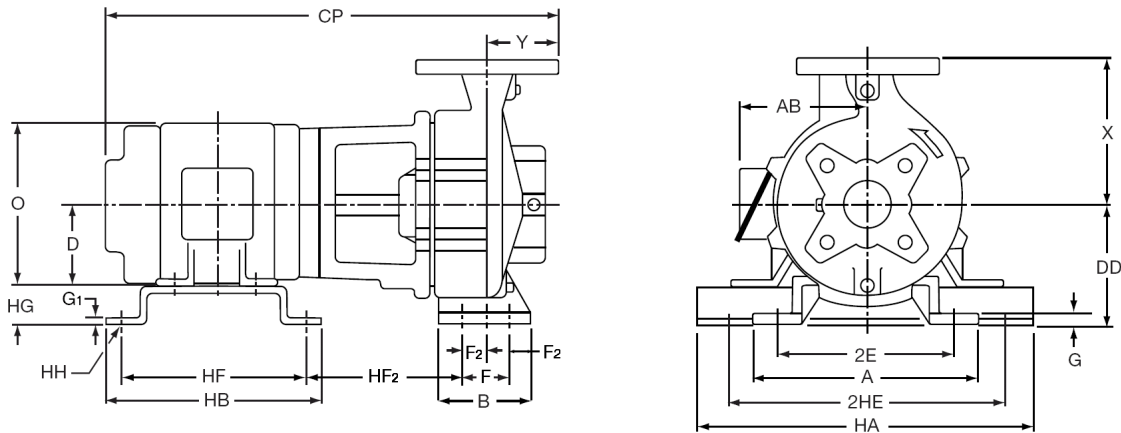

FLANGE DIMENSIONS IN INCHES (MM)	
	SIZE
Discharge	8" (127)
Suction	10" (152)

FLANGES ARE: 125# ANSI - STANDARD

DIMENSIONS – Inches (mm)

STANDARD SEAL

MOTOR FRAME	A	AB	HB	CP	D	HF	G	G1	H	HH	HA	F2	2E	2HE	HF2	B	F	O	HG	DD	X	Y
284JP	21.44 (545)	11.88 (302)	17.38 (441)	34.61 (879)	7 (178)	15.88 (403)	0.62 (16)	0.25 (6)	0.75 (19)	0.75 (19)	27.5 (698)	2.95 (75)	17.62 (448)	26 (660)	6.2 (157)	7.87 (200)	5.9 (150)	14.19 (360)	7.37 (187)	14.37 (365)	17.32 (440)	4.77 (121)
286JP	21.44 (545)	11.88 (302)	17.38 (441)	36.11 (917)	7 (178)	15.88 (403)	0.62 (16)	0.25 (6)	0.75 (19)	0.75 (19)	27.5 (698)	2.95 (75)	17.62 (448)	26 (660)	7.70 (195)	7.87 (200)	5.9 (150)	14.19 (360)	7.37 (187)	14.37 (365)	17.32 (440)	4.77 (121)
324JP	21.44 (545)	14.06 (357)	19 (483)	37.55 (954)	8 (203)	17.5 (445)	0.62 (16)	0.25 (6)	0.75 (19)	0.75 (19)	27.5 (698)	2.95 (75)	17.62 (448)	26 (660)	6.38 (162)	7.87 (200)	5.9 (150)	16.38 (416)	6.37 (162)	14.37 (365)	17.32 (440)	4.77 (121)
326JP	21.44 (545)	14.06 (357)	19 (483)	39.04 (992)	8 (203)	17.5 (445)	0.62 (16)	0.25 (6)	0.75 (19)	0.75 (19)	27.5 (698)	2.95 (75)	17.62 (448)	26 (660)	7.89 (200)	7.87 (200)	5.9 (150)	16.38 (416)	6.37 (162)	14.37 (365)	17.32 (440)	4.77 (121)
364JP	21.44 (545)	15.88 (403)	19.25 (489)	40.42 (1026)	9 (229)	17.75 (451)	0.62 (16)	0.25 (6)	0.75 (19)	0.75 (19)	27.5 (698)	2.95 (75)	17.62 (448)	26 (660)	7.57 (193)	7.87 (200)	5.9 (150)	18.31 (360)	5.37 (136)	14.37 (365)	17.32 (440)	4.77 (121)
365JP	21.44 (545)	15.88 (403)	19.25 (489)	40.42 (1026)	9 (229)	17.75 (451)	0.62 (16)	0.25 (6)	0.75 (19)	0.75 (19)	27.5 (698)	2.95 (75)	17.62 (448)	26 (660)	8.57 (218)	7.87 (200)	5.9 (150)	18.31 (360)	5.37 (136)	14.37 (365)	17.32 (440)	4.77 (121)

Dimensions are subject to change. Not to be used for construction purposes unless certified.

Marlow Commercial Pool Pumps
by

Xylem Inc.
8200 N. Austin Avenue
Morton Grove, IL 60053
Phone: (847)966-3700
Fax: (847)965-8379
www.gouldswatertechnology.com



Goulds is a registered trademark of Goulds Pumps, Inc. and is used under license.
© 2013 Xylem Inc.