



FEATURES

Pump:

- 1½" NPT discharge and open suction
- Maximum suspended solids ½"
- Capacities: to 37 U.S. GPM
- Total heads: to 145 feet TDH
- Temperature: 104°F (40°C) continuous, 140°F (60°C) intermittent
- Maximum submergence: to 65 feet (20 m)
- Continuous duty rated, non-overloading motor

Motor:

- Single phase
- 115 or 230 V, 60 Hz
- PSC design for excellent efficiency
- Class F insulation
- Non-overloading
- Built-in, automatic reset, thermal overload protection
- 10' Power cord with bare leads

These multi-stage, high head, bottom suction pumps are ideal for use in the following applications:

Filtered On-Site Effluent Systems, Cistern Booster Systems, Shallow Dug Wells, Shore Wells, and Aeration.

REDJACKET SERIES FE

MULTI-STAGE, BOTTOM-INLET, HIGH HEAD SUBMERSIBLES WASTEWATER



PUMP FEATURES • AISI 304 SS • CORROSION RESISTANT, NON-TOXIC, NON-LEACHING

- FDA compliant, glass filled Noryl®. Corrosion and abrasion resistant.
- Silicon carbide sealing faces; all metal components of AISI type 300 stainless steel running in protected oil chamber.
- BUNA-N
- Constructed of AISI type 304 series stainless steel.
- AISI type 304 stainless steel high strength keyed pump shaft with impeller locking cap screw.
- 1¼" NPT vertical discharge connection.
- Detachable for easy clean out.

Component	Material
Outer casing and upper support	Stainless steel (AISI 304)
Motor casing	Stainless steel (AISI 304)
Suction strainer	Stainless steel (AISI 304)
Motor shaft	Stainless steel (AISI 304)
Impeller	Noryl
Diffuser	Stainless steel (AISI 304)
Mechanical seal housing	Technopolymer
Elastomers	BUNA-N
Inner mechanical seal	Silicon carbide / silicon carbide
Outer lip seal	Nitrile rubber

MODEL INFORMATION

Model No.	HP	Volts	Stages	Maximum Amps	Minimum Circuit Breaker	Phase	RPM	Power Cord	Discharge Connection	Weight (lbs.)	"L" Dimension (in.)
16FE0511	½	115	3	9.0	15	1	3450	10' 16 AWG with bare leads	1¼" NPT	28	19.8"
26FE0511											
16FE0512		230		4.5	10						
26FE0512											

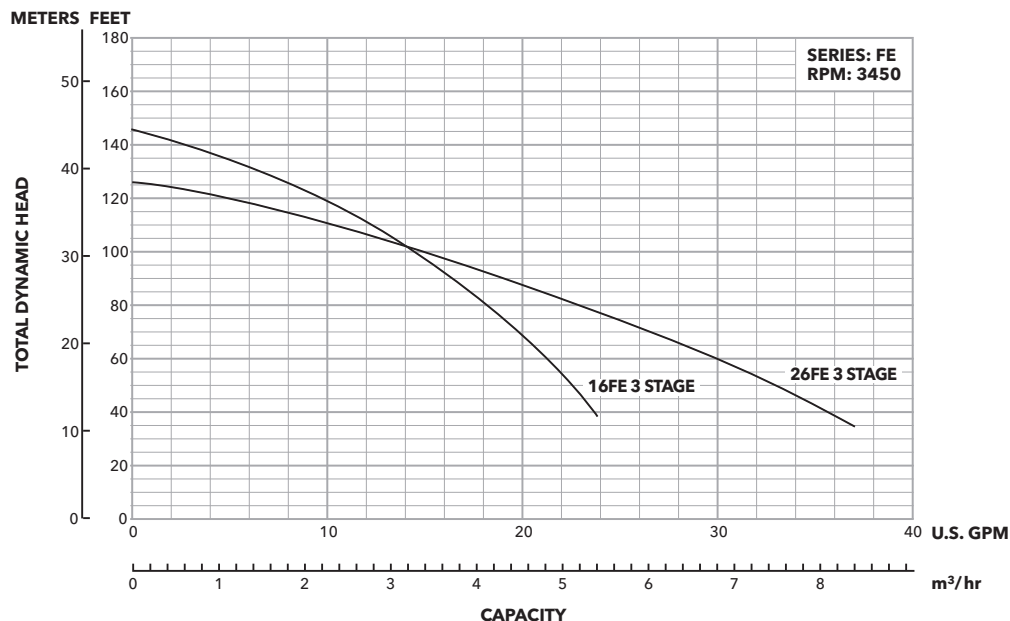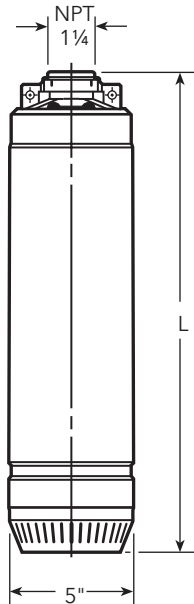

xylem
Let's Solve Water

Xylem Inc.
2881 East Bayard Street Ext., Suite A
Seneca Falls, NY 13148
Phone: (866) 325-4210
Fax: (888) 322-5877
goulds.com/redjacket

Red Jacket Water Products is a trademark of Xylem Inc. or one of its subsidiaries. Goulds is a registered trademark of Goulds Pumps, Inc. and is used under license.

© 2017 Xylem Inc. BRJFE R1 January 2017