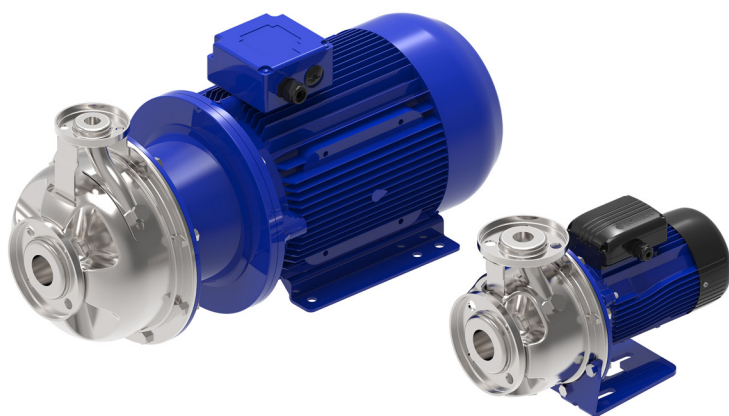




Quick Startup Guide




e-SHE, e-SHS

i





i


\bar{p}	< 74,5 Lpa
φ	< 50% @ 40°C (104°F)
\uparrow	0+40°C (32+104°F) 0+50°C (32+122°F) ? →





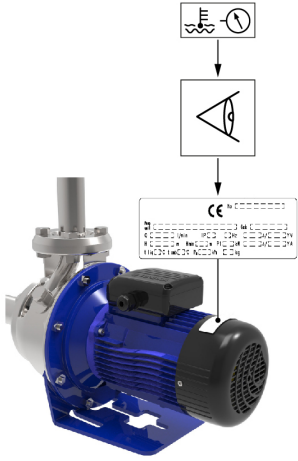


i

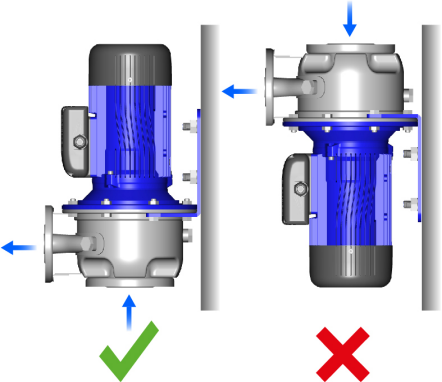
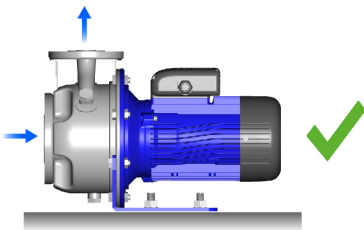


i

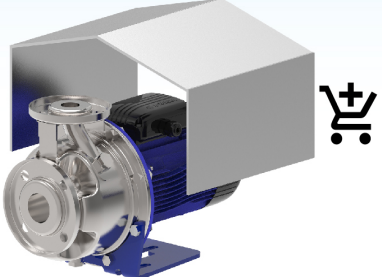


   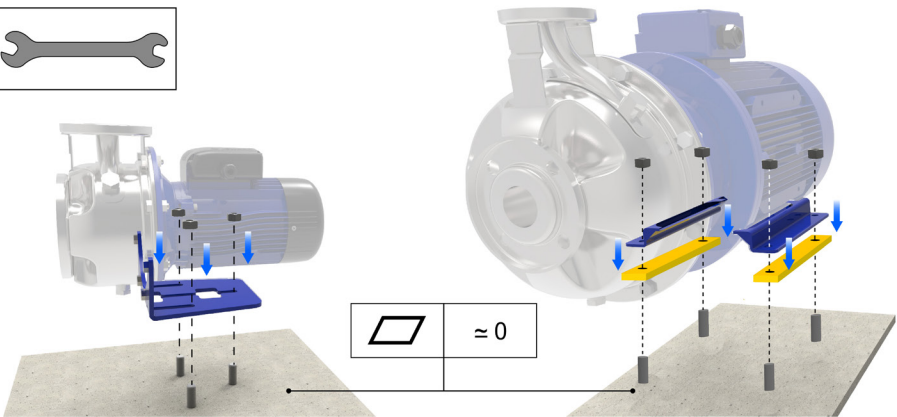 1**2****3**


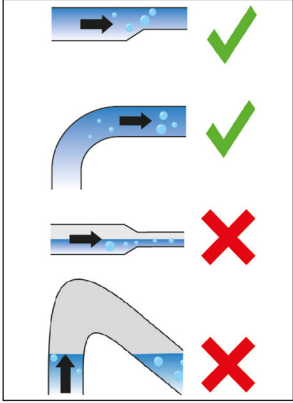
 
4




5

 

6

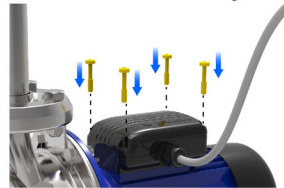  


7a

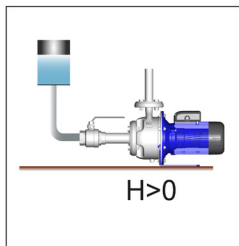

7b



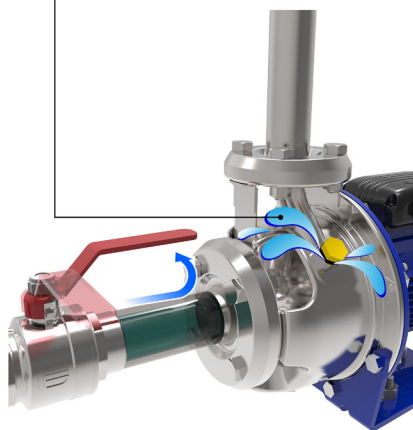
7c




7d





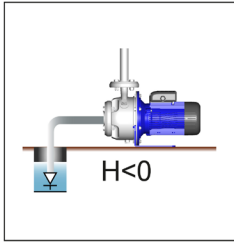
8a




8b

 


8c

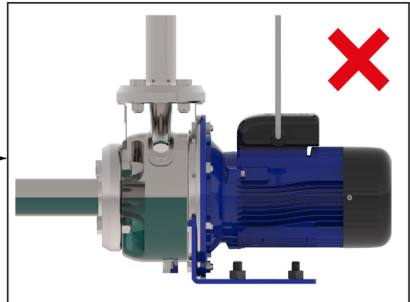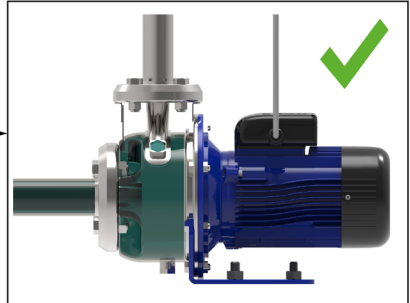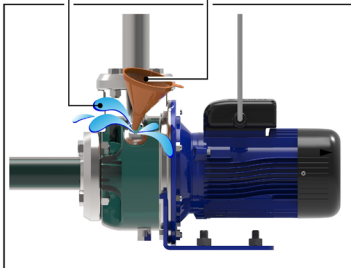

8d


 


9a

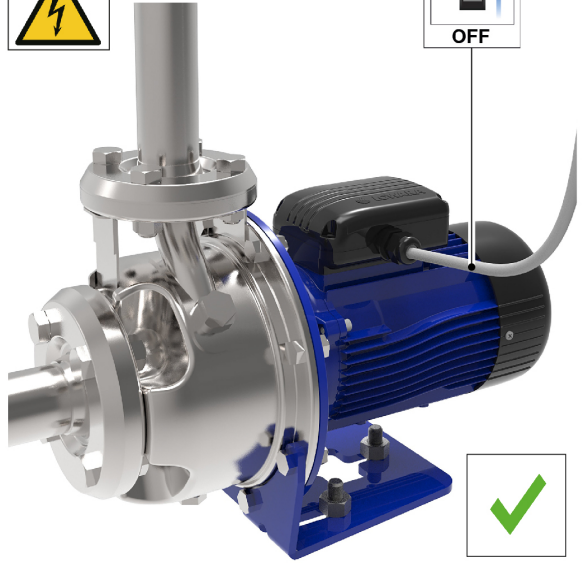

9b

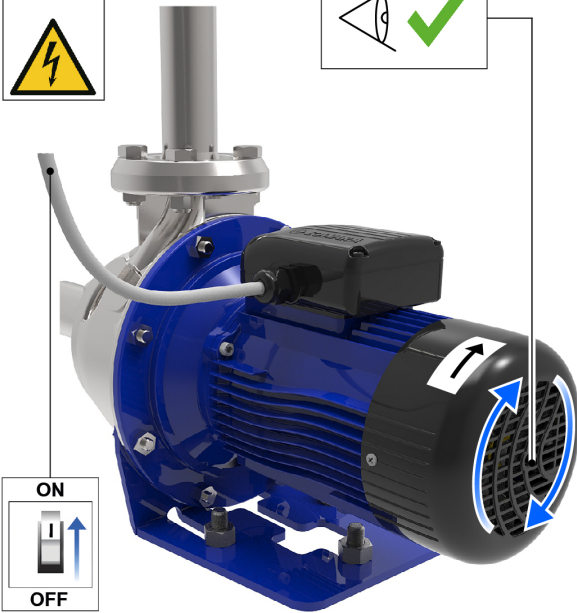 i



Xylem |'zīləm|



Xylem Service Italia S.r.l.
Via Vittorio Lombardi 14
Montecchio Maggiore (VI) 36075
Italy

© 2020 Xylem, Inc.

Cod. 001080182G rev.A ed.01/2020