



**28300 Series Performance Curve - Standard Pressure 080 FG Neoprene Impeller**  
**Viscosity 1-500 Cp - Starting Torques Fwd 6.5 Nm / Rev 15.2 Nm**

For models 28300, 28320, 28330, and 28340 in Europe

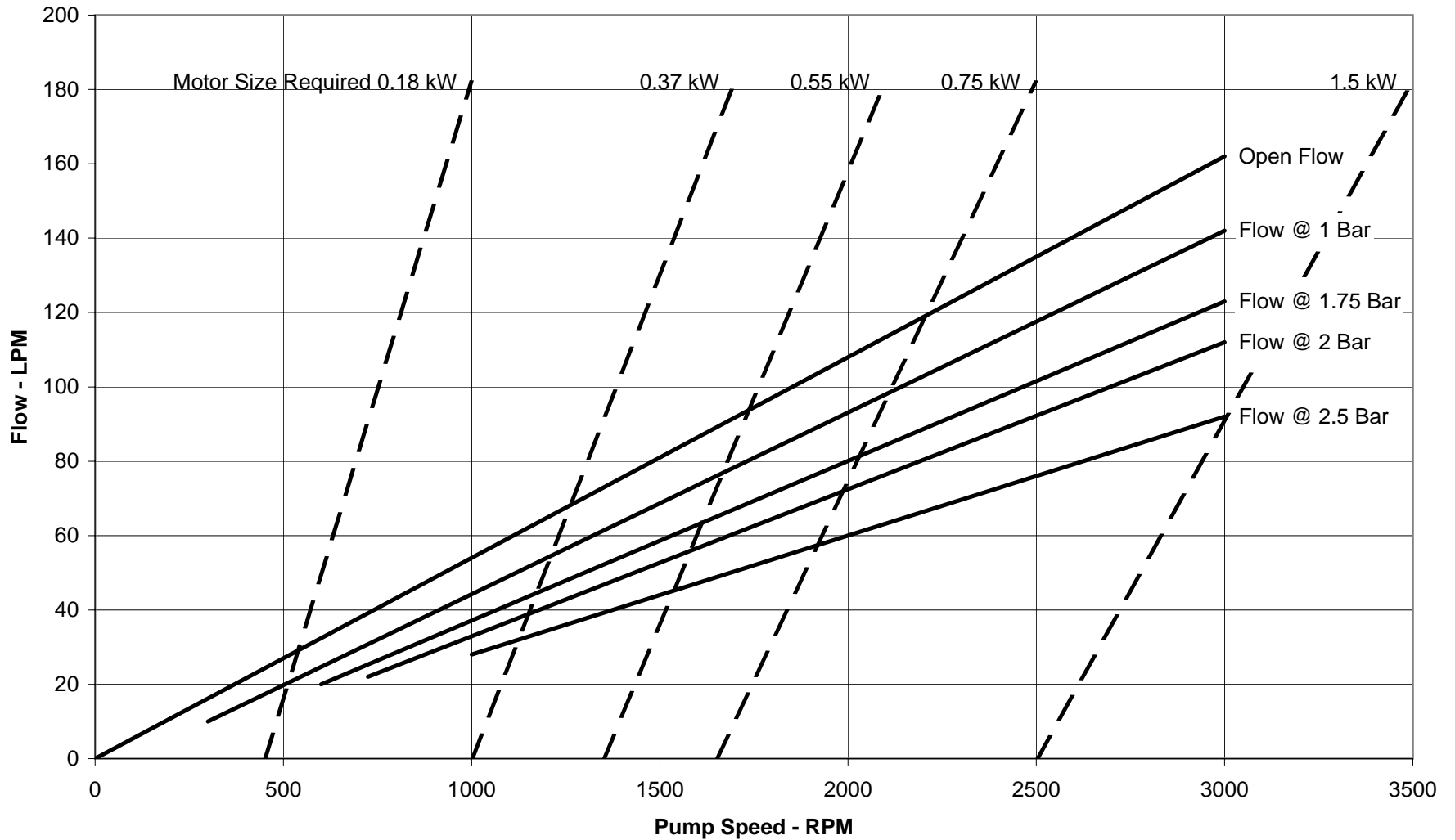


**28300 Series Performance Curve - High Pressure 080 FG Neoprene Impeller**  
**Viscosity 1-500 Cp - Starting Torques Fwd 10.7 Nm / Rev 22.1 Nm**

For models 28300, 28320, 28330, and 28340 in Europe

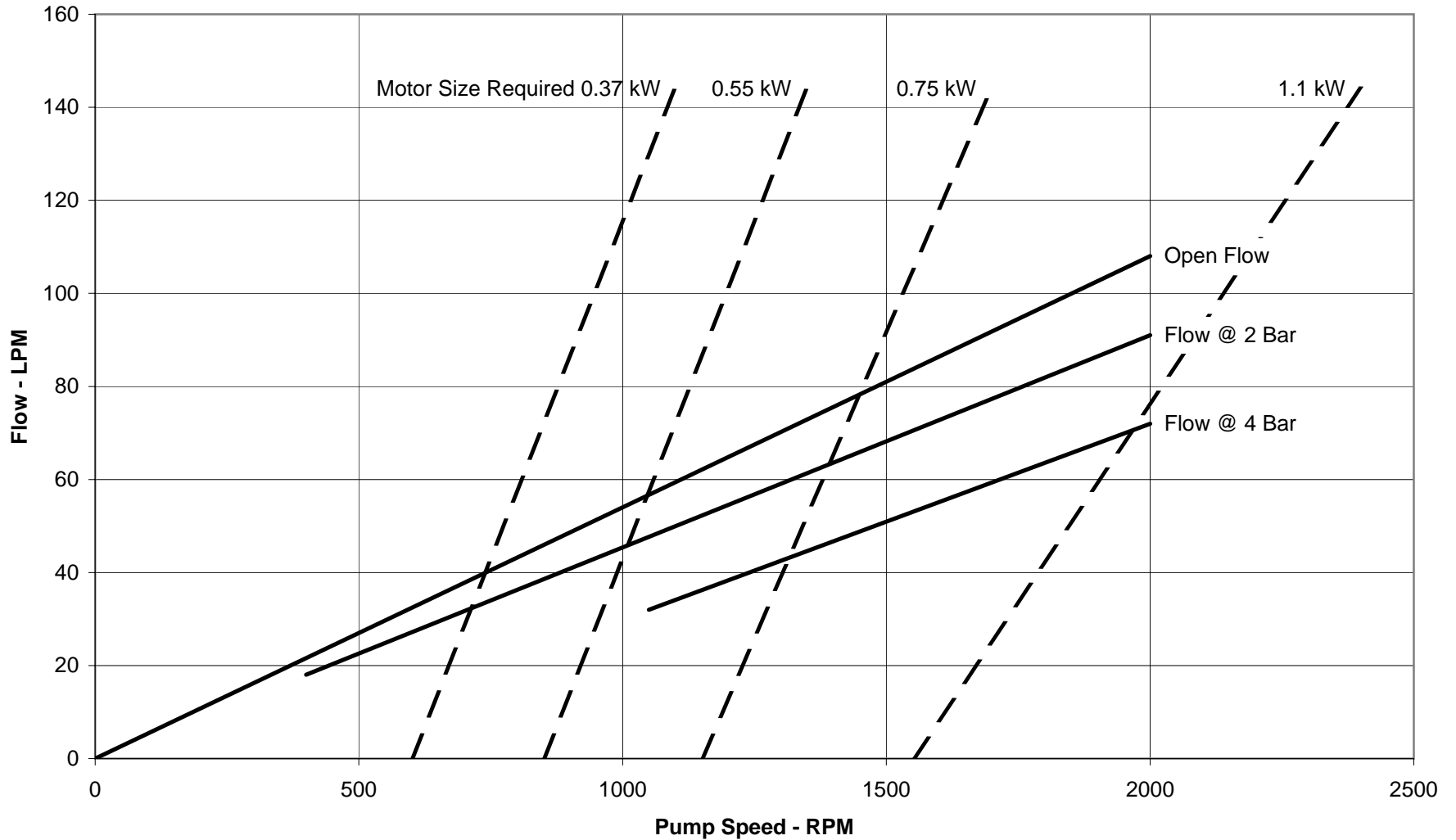

**28300 Series Performance Curve - High Pressure FG Neoprene Impeller**  
**Viscosity 500-2000 Cp - Starting Torques Fwd 10.7 Nm / Rev 22.1 Nm**

For models 28300, 28320, 28330, and 28340 in Europe

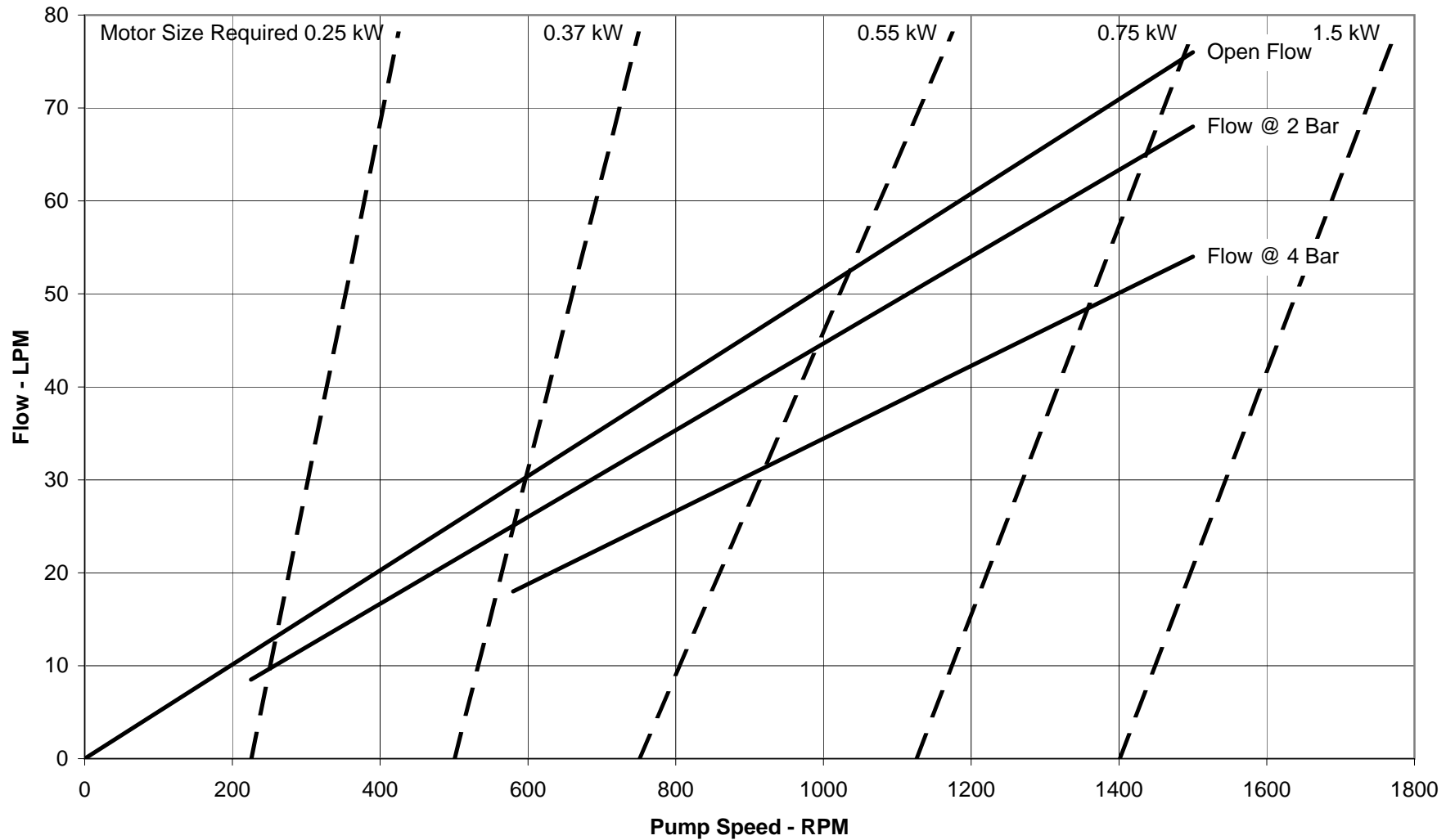

**28300 Series Performance Curve - High Pressure FG Neoprene Impeller**  
**Viscosity 2000-4000 Cp - Starting Torques Fwd 10.7 Nm / Rev 22.1 Nm**

For models 28300, 28320, 28330, and 28340 in Europe

