



28400 Series Performance Curve - Standard Pressure 200 FG Neoprene Impeller
Viscosity 1-500 Cp - Starting Torques Fwd 17.6 Nm / Rev 58.2 Nm

For models 28400, 28420, 28430, and 28440 in Europe

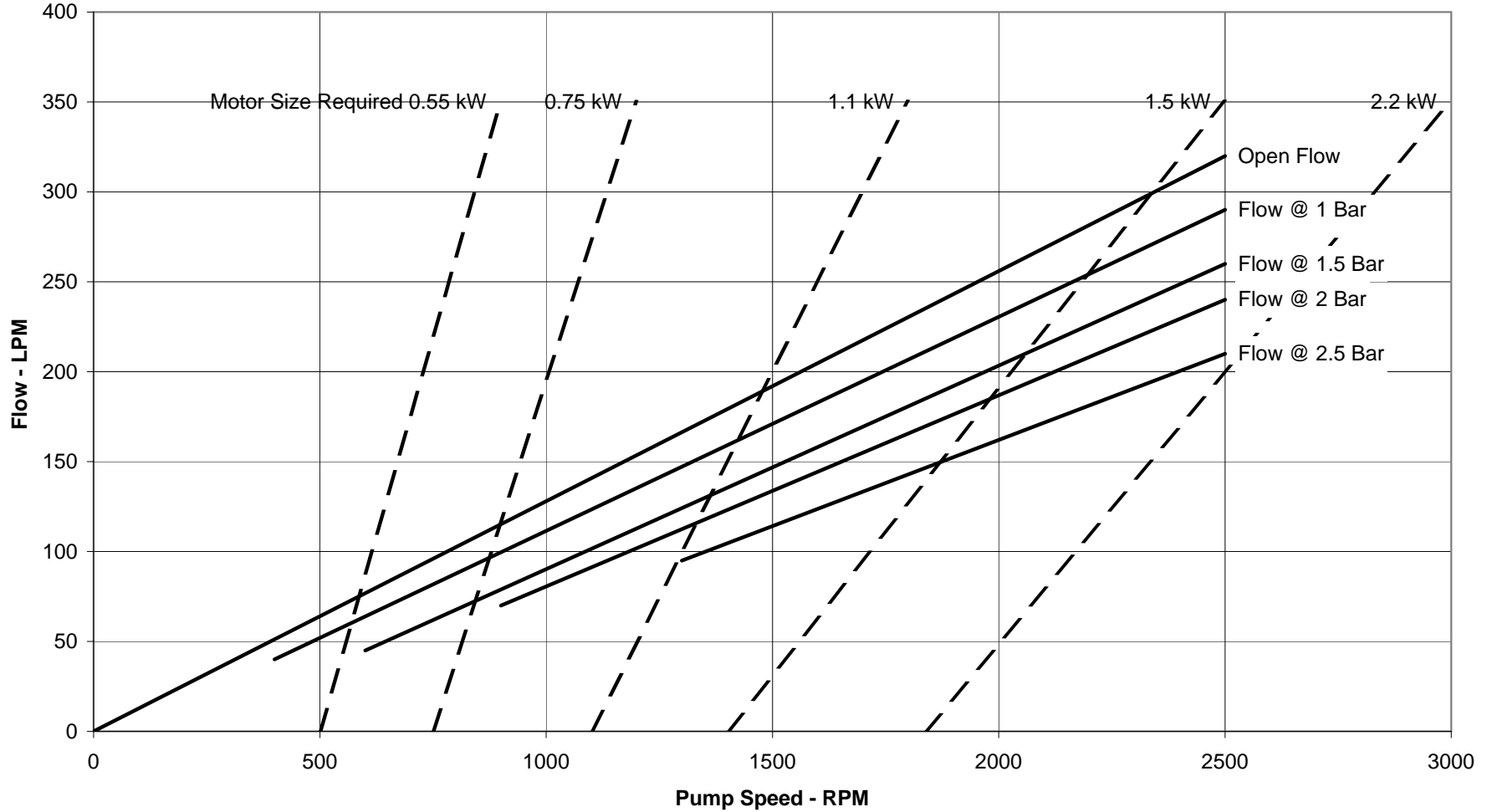


28400 Series Performance Curve - High Pressure 200 FG Neoprene Impeller
Viscosity 1-500 Cp - Starting Torques Fwd 35.2 Nm / Rev 54.2 Nm

For models 28400, 28420, 28430, and 28440 in Europe

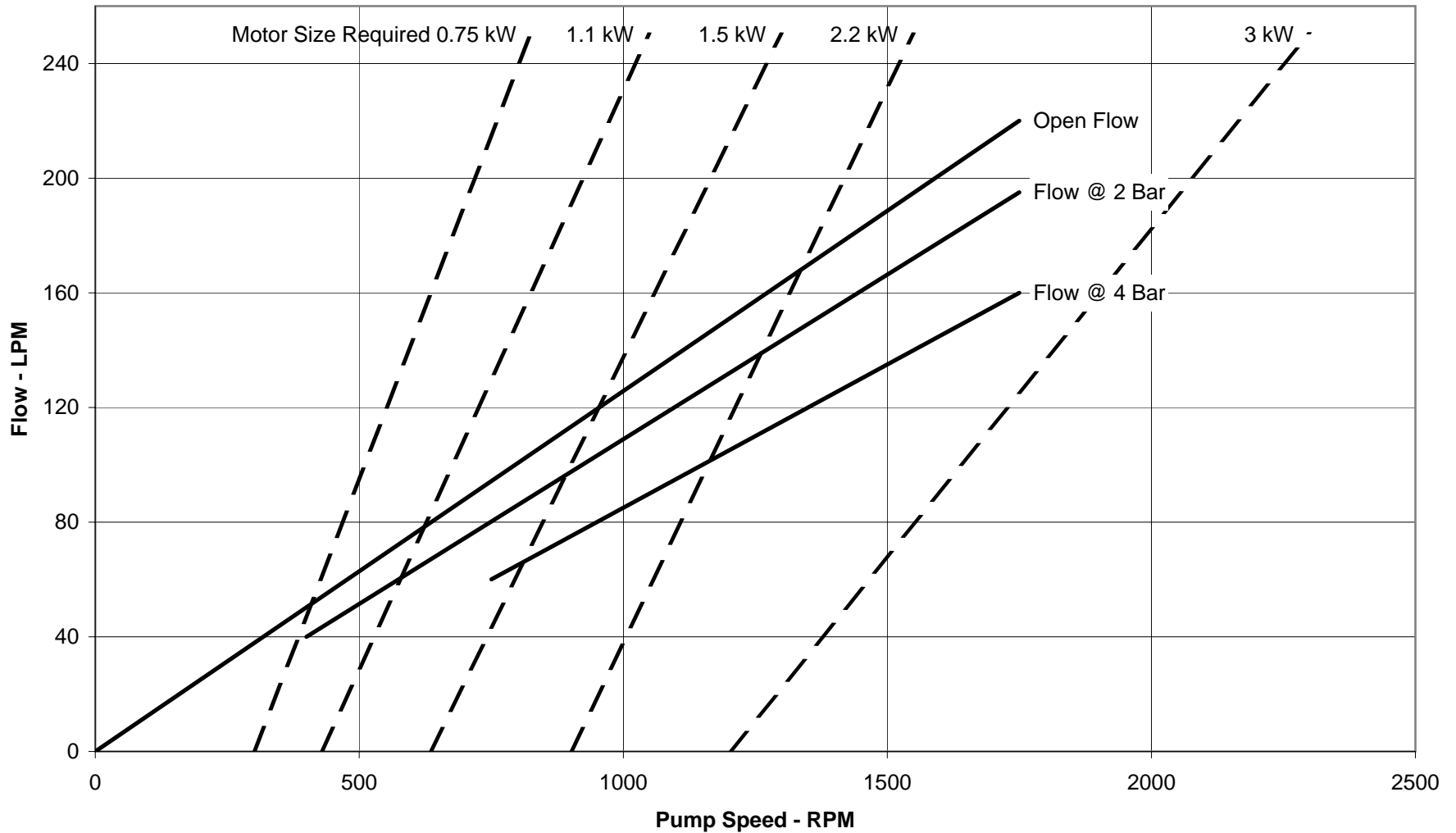

28400 Series Performance Curve - High Pressure FG Neoprene Impeller
Viscosity 500 - 2000 Cp - Starting Torques Fwd 35.2 Nm / Rev 54.2 Nm

For models 28400, 28420, 28430, and 28440 in Europe

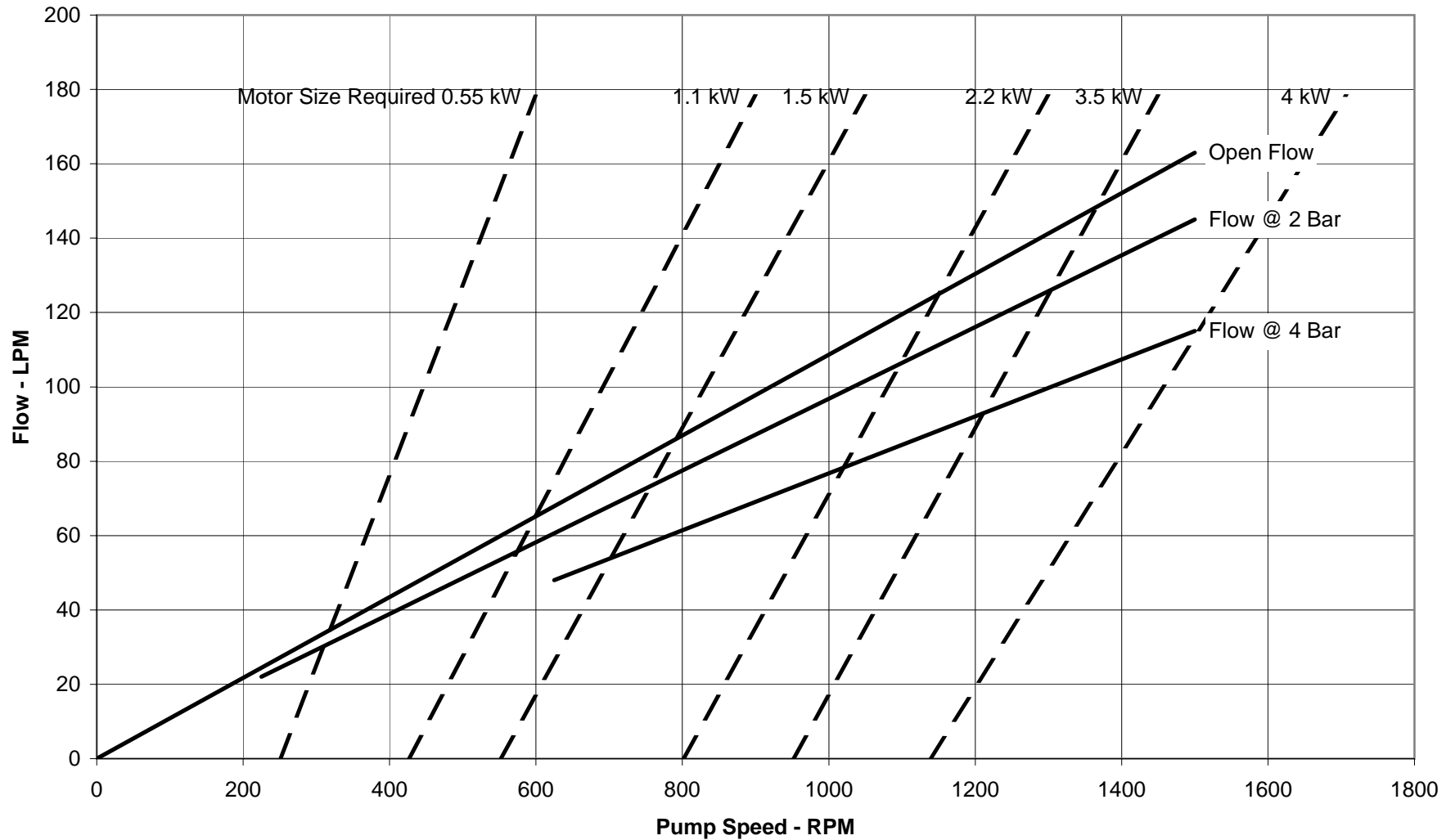

28400 Series Performance Curve - High Pressure FG Neoprene Impeller
Viscosity 2000 - 4000 Cp - Starting Torques Fwd 35.2 Nm / Rev 54.2 Nm

For models 28400, 28420, 28430, and 28440 in Europe

