


28500 Series Performance Curve - Standard Pressure 370 FG Neoprene Impeller
Viscosity 1-500 Cp - Starting Torques Fwd 33.2 Nm / Rev 59.7 Nm


For models 28500, 28520, 28530, and 28540 in Europe

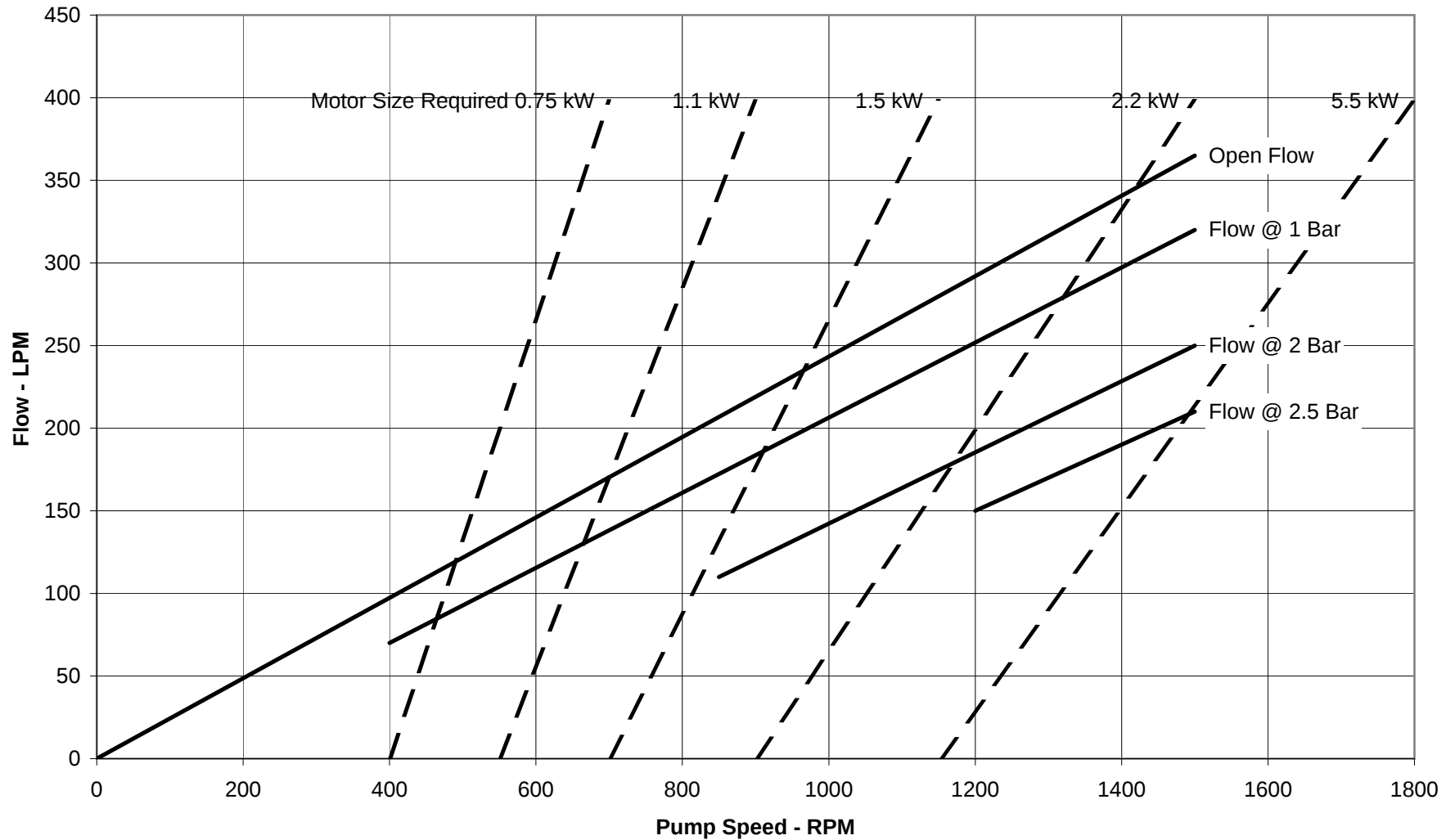

28500 Series Performance Curve - High Pressure 370 FG Neoprene Impeller


Viscosity 1-500 Cp - Starting Torques Fwd 37.3 Nm / Rev 66.4 Nm

For models 28500, 28520, 28530, and 28540 in Europe

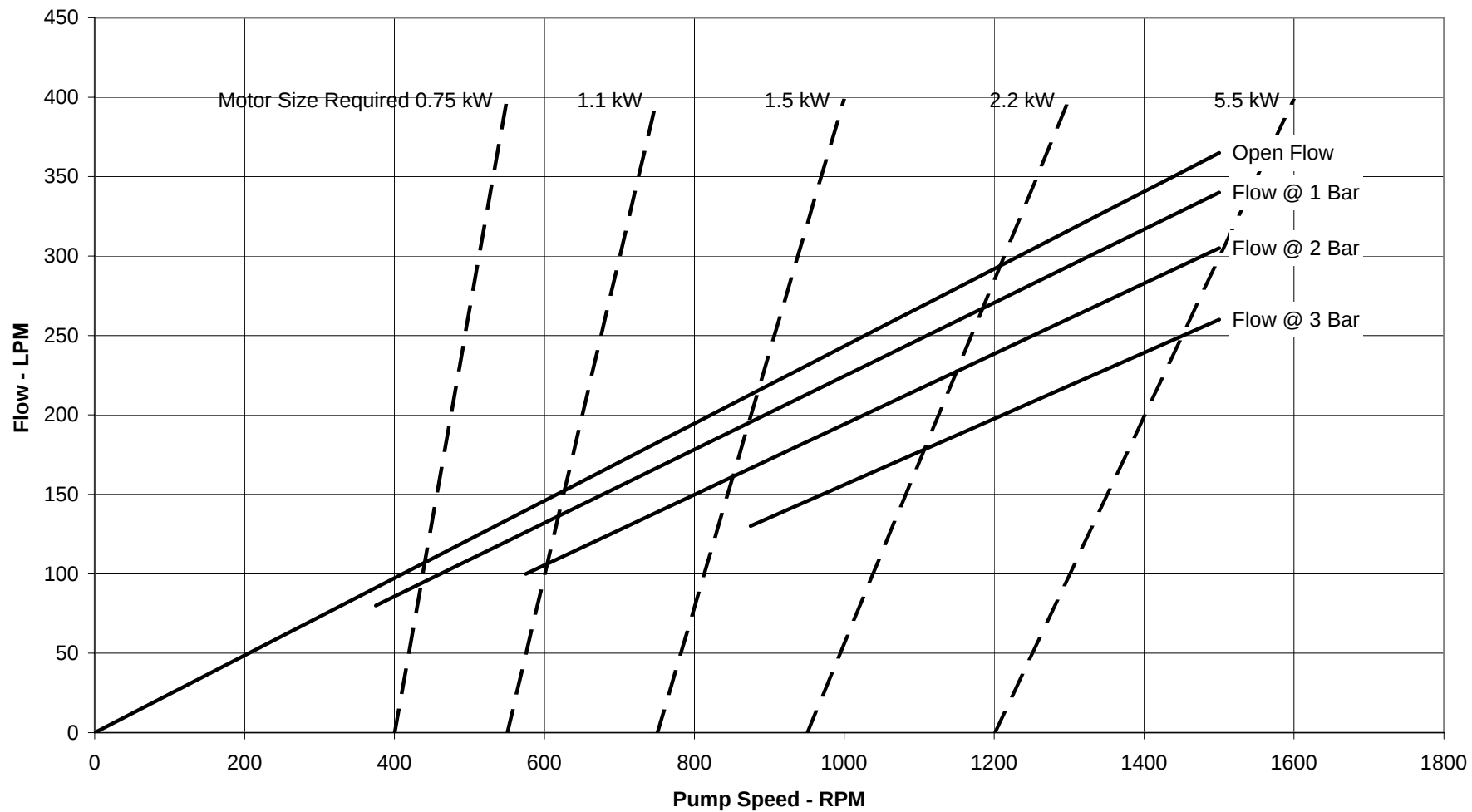

28500 Series Performance Curve - High Pressure FG Neoprene Impeller
Viscosity 500 - 2000 Cp - Starting Torques Fwd 37.3 Nm / Rev 66.4 Nm

For models 28500, 28520, 28530, and 28540 in Europe

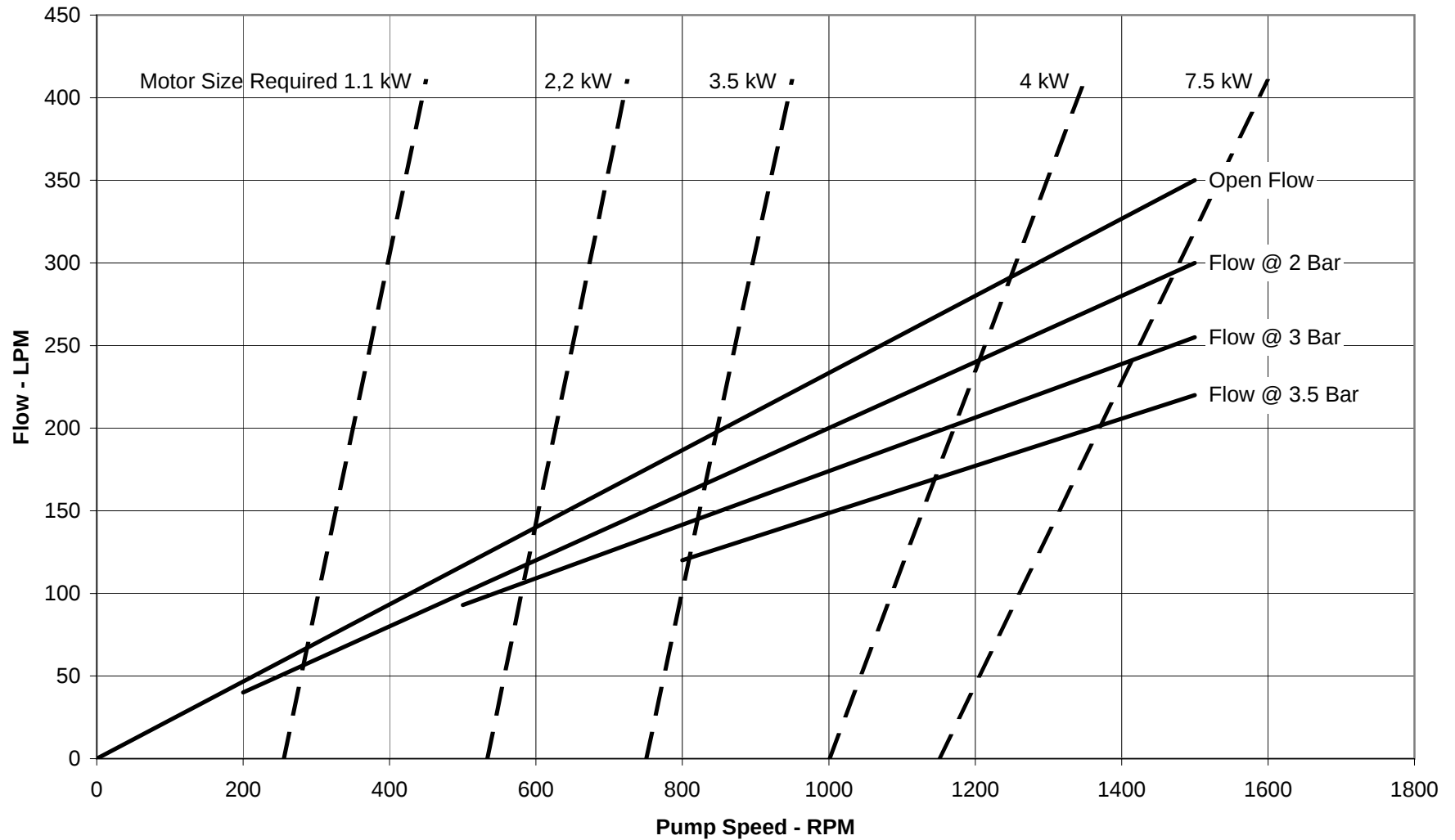

28500 Series Performance Curve - High Pressure FG Neoprene Impeller
Viscosity 2000 - 4000 Cp - Starting Torques Fwd 37.3 Nm / Rev 66.4 Nm
For models 28500, 28520, 28530, and 28540 in Europe

