




a xylem brand

Water Entry Pressure Regulator

Models

- 44411-1045 Flush-mount, Garden Hose x 1/2"-14 pipe
- 44411-2045 Flush-mount w/ Chrome Flange
- 44412-1045 Flush-mount, Garden Hose x Quick Connect Port
- 44412-2045 Flush-mount w/ Chrome Flange

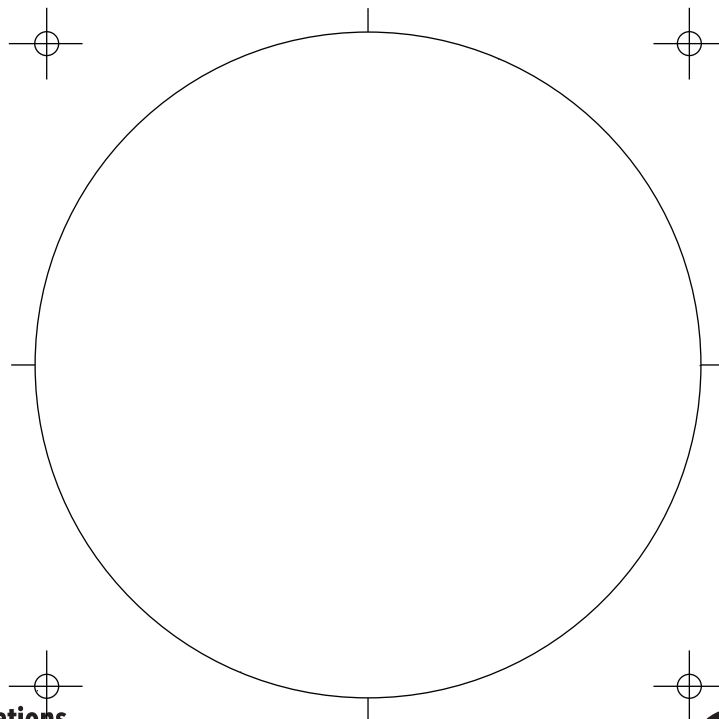

Specifications

Pressures: 125 psi (8.6 bar) max. inlet pressure.
45 psi (3.1 bar) regulator output.
Working Temperature: 33-150°F (1-65°C).

Installation/Operation

Use this card as a template. Flush-mount model may be mounted on a panel or bulkhead and plumbed directly to the fresh water system between the water system pump and the water heater (if fitted). Water pressures from 46-125 psi will be regulated down to 45 psi. Lower pressures will pass through unregulated.
Variance is ± 5 psi.



© 2016 Xylem Inc. All rights reserved. Jabsco is a trademark of Xylem Inc. or one of its subsidiaries.
43002-0911 Rev. E 9/2016