



LANSERAS HÖSTEN
2013!

BIBO IS BACK!


PÅLITLIGARE ÄN NÅGONSIN

DIN UTMANING. VÅR UPPGIFT


FLYGT
a xylem brand

Pålitligare än någonsin


2830.180

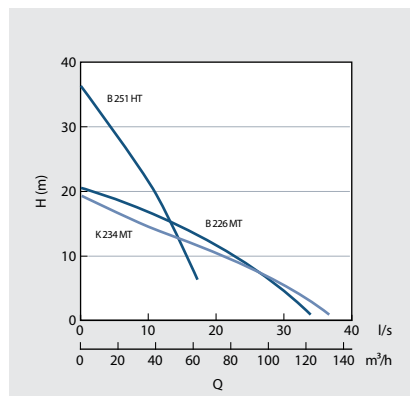


2840.180

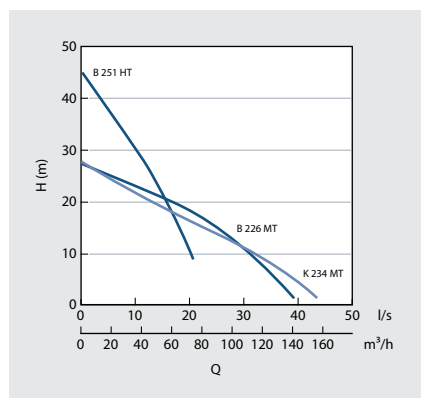

2860.180

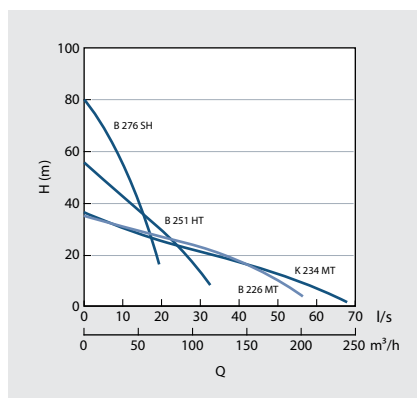

2870.180

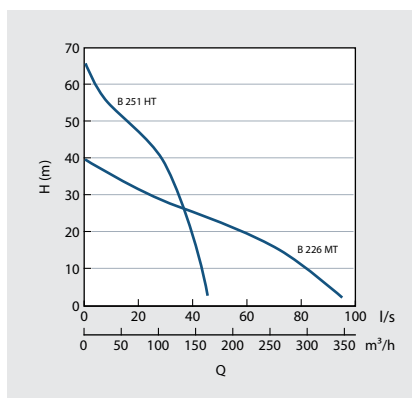

SH=Super high head HT=High head MT=Medium head B=Wear resistant impeller K=Open impeller

Fakta

Modell	L2830	2840	2860	2860 SH	2870
Märkeffekt (kW)	3,2-3,7	5,6	10	10	18
Spänning V/3-fas	220-1000/3~	220-1000/3~	220-1000/3~	220-1000/3~	220-1000/3~
Strömstyrka A	7,6	11	21	21	32
Vikt (kg)	54	56	91	106	125
Höjd (mm)	762	762	889	975	991
Diameter (mm)	367	367	425	425	500
Utlopp Ø (cm)	3"/4"	3"/4"	4"/6"	3"	4"/6"
Sugsilens hål (mm)	10	10	10	10	12
Max temp +70 °C	JA	JA	JA	JA	JA